


Data Sheet

Color Heat Shrinking Tube kit set,
2:1 564pcs/set

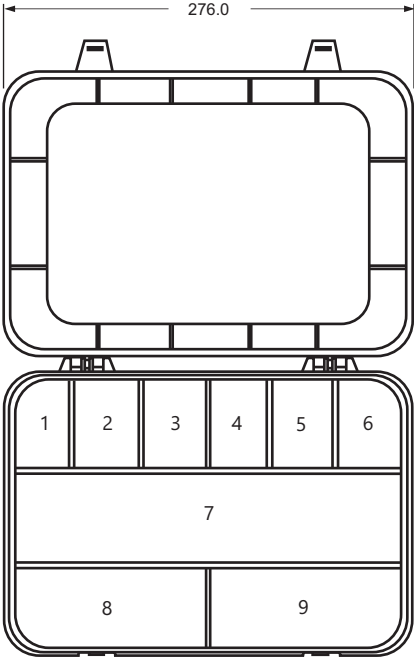

Specification
Shrinking Ratio: 2:1
Operating Temperature: -50°C ~ 125°C
Shrinking Temperature:
Start from 70°C , full recovery at 120°C
Flammability: VW-1

Content :

SECTION	Dia. Ø (mm)		Length(mm)	Color					Total qty.
	Before shrinking	After shrinking		Black	Yellow	White	Red	Blue	
1	1.2	0.6	40	25	25	25	25	25	125
2	1.6	0.8	40	25	25	25	25	25	125
3	2.4	1.2	40	25	25	25	25	25	125
4	3.2	1.6	40	20	20		20	20	80
5	4.8	2.4	40	10	10		10	10	40
6	6.4	3.2	40	5	5		5	5	20
7	1.2	0.6	250					5	
	1.6	0.8	250				5		
	3.2	1.6	250					5	
	4.8	2.4	250		5				
	6.4	3.2	250	5					
	9.5	4.8	250	3					28
8	9.5	4.8	125		4		4	4	12
9	12.5	6.4	125		3		3	3	9