



Data Sheet

RoHS HI-REL IC socket, Gold/Tin, Pin:7.43mm

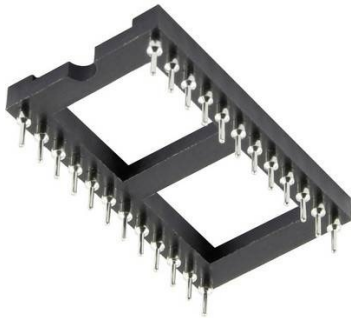

Drawing:

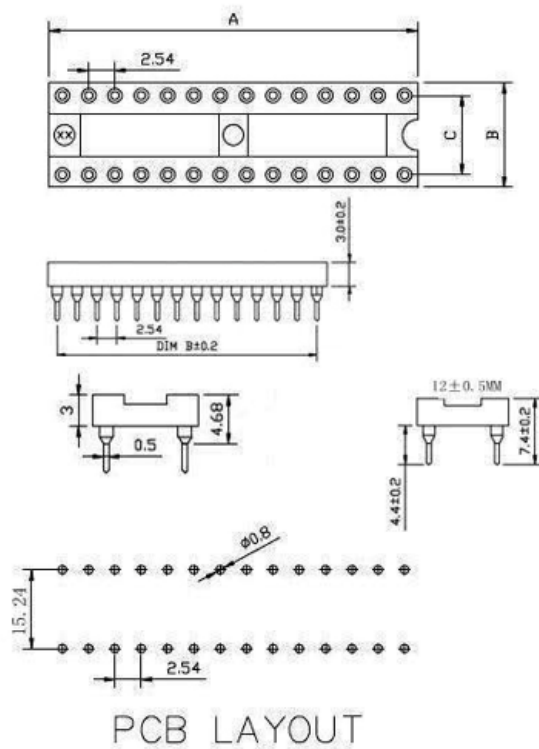

BN	No. of pins	A	B	C
1572708	24	30.48	17.78	15.24
1572709	32	40.64	17.78	15.24
1565628	48	61.01	17.78	15.24

Data Sheet

Technical data

Current rating: 3 Amp

Insulation resistance: 1000 m Ω min

Contact resistance: 20 m Ω

Withstanding voltage: AC 500 V min

Operating temperature: -40 °C ~ +105 °C

Contact material: Copper Alloy and Gold Flash

Insulation material: Polyester. UL94-0 PBT

Colour: Black

General Tolerance: x. \pm 0.30

x.x \pm 0.25

x.xx \pm 0.15