
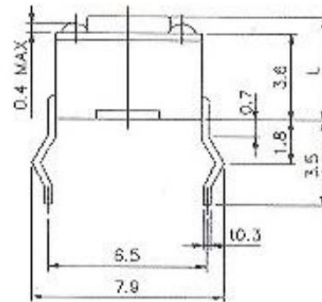


Data Sheet

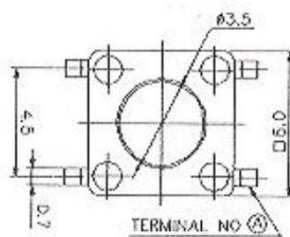

1. Rating : DC12V 50mA
2. Travel : 0.25 ± 0.1 mm
3. Operating Force : 100, 130, 160, 250 ± 50 gf
4. Contact Resistance : $100\text{m}\Omega$ Max
5. Life : 100,000 Cycles Min

Knob Height mm

Code	Blank	A	B	C	D	E	F	G	H	I	J	K	L	M
Standard(L)	4.3	5	6	6.3	7	7.3	8	8.5	9.5	12.5	13.0	13.5	17	45
Bracket Type(L)	3.15	3.85	4.85	5.15	5.85	6.15	6.85	7.35	8.35	11.35	11.85	12.35	15.85	3.35