

# Datasheet

Item no. 1565766

V1\_0917\_01\_en


## Mini Solar cell panel



Item no.	Dimension (±0.3)	Thickness (±0.3)	Solar cell Type	Maximum Power (P.max)	Power Tolerance	Rated Voltage (V.mp)	Rated Current(Imp)	Open Circuit Voltage(Voc)	ShortCircuit Current(Isc)	Net Weight Approx.
1565766	30x70mm	2.7mm	Polycrystalline	0.2W	±5%	5V	0.04A	6.2V	0.042A	0.007kg

Operating Temperature and Humidity: -20°C~80°C and 25%~95% RH

Storage Temperature and Humidity: 10°C~65°C and 15%~75% RH

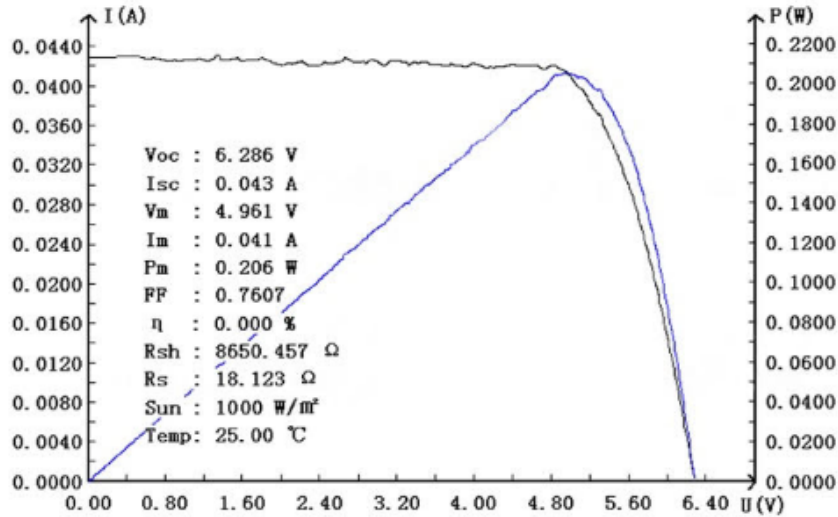

型号: 70X30-10 规格: 0.20W/5V

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com).

All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represents the technical status at the time of printing.

© Copyright 2017 by Conrad Electronic SE.