

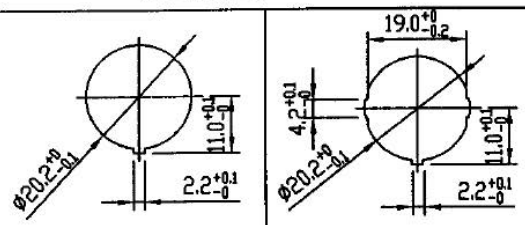
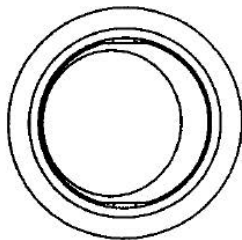


Rocker Switch, 16A/125VAC (10A/250 VAC)

Rating	20A 12VDC	Mounting Hole	
Contact Resistance	50m ohm Max.		Thickness: 2.0~3.0 Thickness: 0.7~3.0
Insulation Resistance	DC 500V 100M ohm Min.		
Dielectric Strength	AC 1500V 1 minute		
Operation Temperature	-20°C~85°C		
Switch Function	3P SPST ON-OFF (LED)		

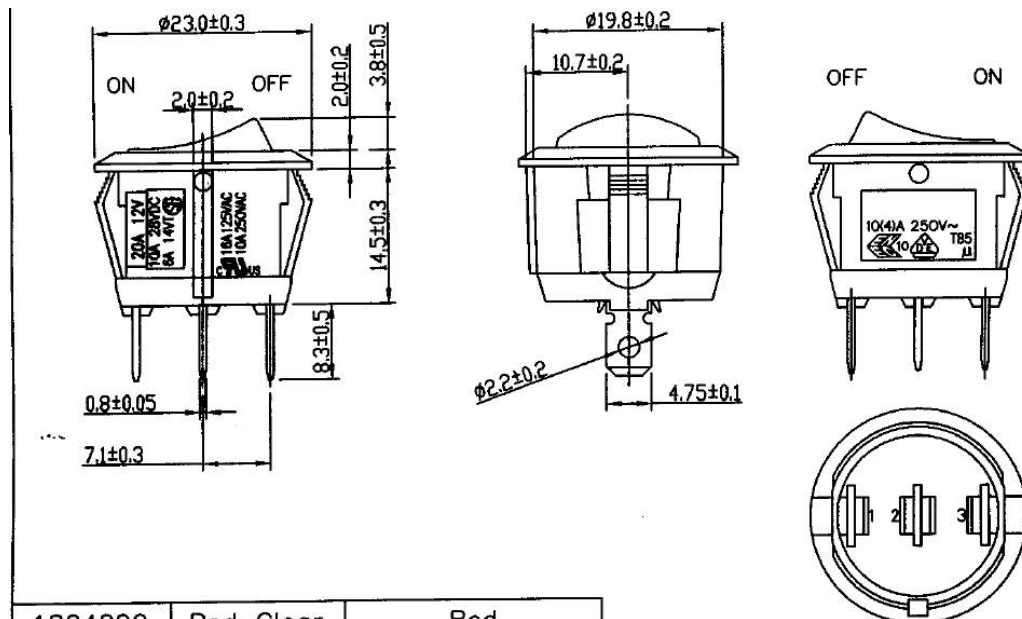

Material:
 Frame: Black, Nylon 66 (94-V2)
 Lens: PC
 Terminals: Silver plated, Copper alloy
 Lamp: LED
 Hot stamping: None

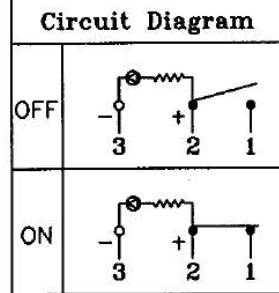

1824290	Red Clear	Red
1822796	Blue Clear	Blue
SCI NO.	Lens Color	LED Color

Unit: mm