
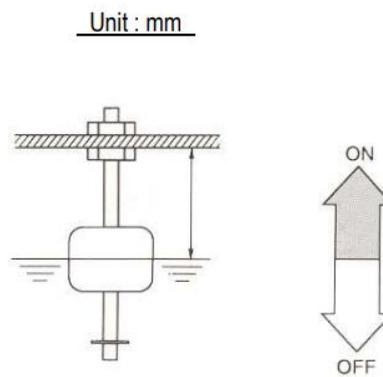


LEVEL SENSOR SWITCH

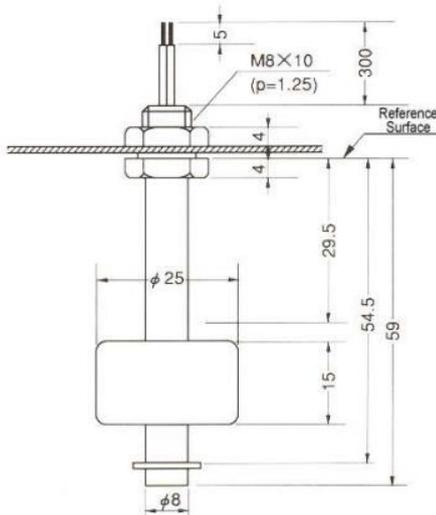

ON	34.0 min.
OFF	41.0 max.

Specifications :

Fluid Applicable		kerosene (0.79)
Material	Case	6 nylon
	Float	NBR (polyform)
Electrical Characteristic	Max. Switching Power	50 W
	Max. Switching Voltage	200 V
	Max. Switching Current	0.6 A
	Contact Withstand Voltage	250 V DC
	Contact Resistance	0.3 Ω max.
Operating Temperature		-20 to +70°C

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com).

All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represents the technical status at the time of printing.