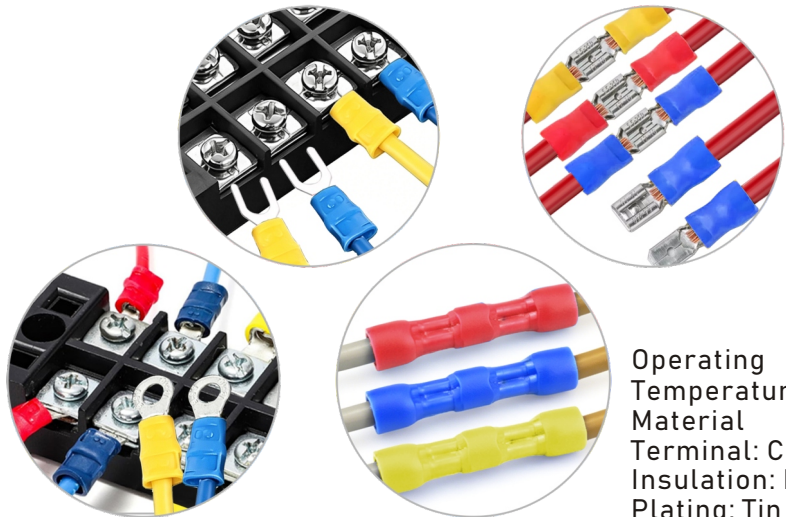


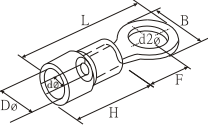
Data Sheet

Connector Kit Set 1000pcs/Set

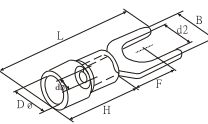


Operating Temperature: 75°C
Material
Terminal: Copper
Insulation: PVC
Plating: Tin

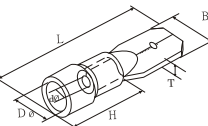
Ring connector

	BN	Color	Cross section(mm ²)	L(mm)	B(mm)	H(mm)	F(mm)	Dø(mm)	dø(mm)	d2(mm)	Piece
				±1	±0.2	±0.5	±0.3	±0.5	±0.2	±0.2	
	1572136	 Blue	1.5-2.5mm ² AWG 16~14	22.5	9.5	10	7.25	4.9	2.3	5.3	120PCS
	1566743	 Yellow	4-6mm ² AWG 12~10	25.5	9.5	13	8.3	6.3	3.4	5.3	60PCS

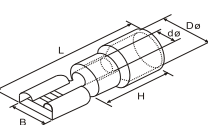
Spade connector

	BN	Color	Cross section(mm ²)	L(mm)	B(mm)	H(mm)	F(mm)	Dø(mm)	dø(mm)	d2(mm)	Piece
				±1	±0.2	±0.5	±0.3	±0.5	±0.2	±0.2	
	1566941	 Blue	1.5-2.5mm ² AWG 16~14	21.2	7.2	10	6.5	4.9	2.3	4.3	120PCS
	N/A	 Yellow	4-6mm ² AWG 12~10	25.2	8.3	12.5	7.5	6.7	3.4	3.7	60PCS

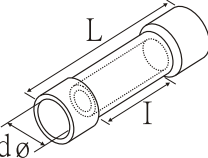
Blade connector

	BN	Color	Cross section(mm ²)	Fits Tab(mm)	L(mm)	B(mm)	H(mm)	T(mm)	Dø(mm)	dø(mm)	Piece
					±1	±0.2	±0.5	±0.1	±0.5	±0.2	
	1566739	 Red	0.5-1.5mm ² AWG 22~16	6.4x0.8	21	6.35	10	0.8	3.5	1.7	120PCS
	1566740	 Blue	1.5-2.5mm ² AWG 16~14	6.4x0.8	21	6.35	10	0.8	4.0	2.3	120PCS

Female spade

	BN	Color	Cross section(mm ²)	Fits Tab(mm)	L(mm)	B(mm)	H(mm)	Dø(mm)	dø(mm)	Piece
					±1	±0.2	±0.5	±0.5	±0.2	
	1564452	 Red	0.5-1.5mm ² AWG 22~16	6.4x0.5	21	6.6	10	3.5	1.7	120PCS
	1565138	 Blue	1.5-2.5mm ² AWG 16~14	6.4x0.8	21	6.6	10	4.0	2.3	120PCS

Butt connector

	BN	Color	Cross section(mm ²)	L(mm)	I(mm)	dø(mm)	Piece
				±1	±0.5	±0.5	
	1570152	 Red	0.5-1.5mm ² AWG 22~16	25	15	4.3	80PCS
	1591364	 Blue	1.5-2.5mm ² AWG 16~14	25	15	4.8	80PCS