


Data Sheet

PVC Insulated Twin Wire, Single core, Black and Red, 10 M

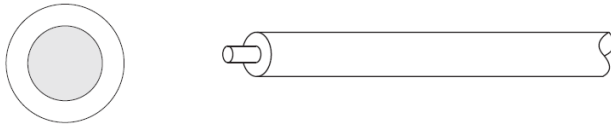

Technical data

Cross-section:	0.2 mm ²
External dia.:	Dia. 1.1 mm ± 0.05
Construction:	1 x dia. 0.5 mm
Material:	
Conductor:	Tined Copper
Insulator:	PVC
Jacket Color:	Black + Red
Dielectric strength:	0.5kv/ 1 min.
Rated voltage:	75 VDC/ 50 VAC
Conductor Resistance:	92.3Ω/KM at 20°C
Insulator Resistance:	15MΩ/KM at 20°C
Flame Class:	94V-2
Operating Temperature:	-10 to 80°C