


Data Sheet

PVC Insulated Twin Wire, Yellow and Brown, 10 M

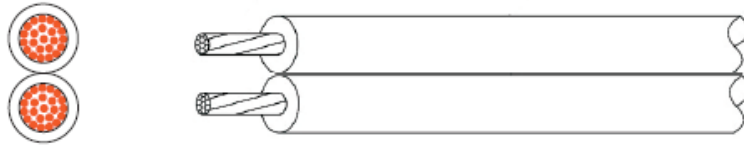

Technical data

Cross-section:	2 x 0.14 mm ²
External dia.:	1.3 x 2.6 mm ±0.1
Construction:	28 x dia. 0.08 mm
Material:	
Conductor:	Cu blank
Insulator:	PVC
Jacket Color:	Black + Red Yellow + Brown
Dielectric strength:	0.5kv/ 1 min.
Rated voltage:	75 VDC/ 50 VAC
Conductor Resistance:	142Ω/KM at 20°C
Insulator Resistance:	15MΩ/KM at 20°C
Flame Class:	94V-2
Operating Temperature:	-10 to 70°C