


Item no.: 1567102

Data Sheet



4-condutor miniature jack

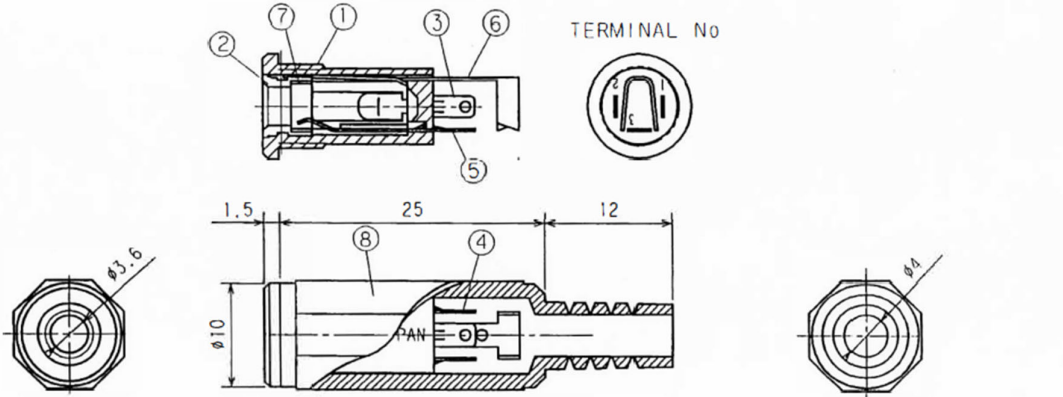

SPECIFICATION

DIELECTRIC STRENGTH : 500V AC FOR ONE MINUTE.

CONTACT RESISTANCE : 50m OHM MAX.

INSULATION RESISTANCE : 100M OHM MIN. AT 500V DC.

8	HANDLE	PE	1			TOLERANCE	SCALE	DATE	DESIG	DRAW	INSPE	APRO
7	INSULATION TUBE	PVC	1									
6	CONTACT 4	BSR t=0.3	1	Ni								
5	CONTACT 3	FAB-EH t=0.25	1	Ni		MODEL		QTY	PART NAME	4-con.3.5mm Inline Jack		
4	CONTACT 2	FAB-EH t=0.25	1	Au		型式			品名			
3	CONTACT 1	FAB-EH t=0.25	1	Ni		MATERIAL				DRAW. NO		
2	SLEEVE	BSBM	1	Ni		材質				図番		
1	HOUSING	PA	1			FINISH						
LET	PART NAME	MATERIAL	QTY	FINISH	NOTE	処理						