


## Data Sheet

### Flat band cable

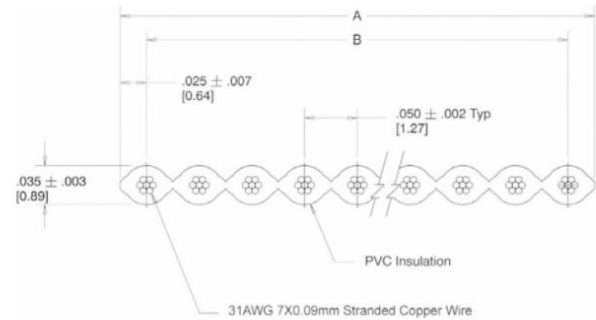

### Technical data

BN	1567185	1567186	1567187	1567188
Pole	10	14	20	40
Outer dimension (A x B)	12.7 x 11.43 mm	17.78 x 16.51 mm	25.40 x 24.13 mm	50.8 x 49.53 mm
Grid pitch	RM 1.27			
Cross section	10 x 0.035 mm <sup>2</sup>	14 x 0.035 mm <sup>2</sup>	20 x 0.035 mm <sup>2</sup>	40 x 0.035 mm <sup>2</sup>
Strand per conductor	7 x 0.08 mm			
Length	30.5 meter			
Conductor material	Copper			
AWG	32			