
 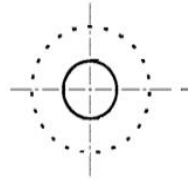


Data Sheet

PET Expandable Braided Hose Series



B/N	Model	Fold Diameter (W)	Bundle Range	Length (L)
		mm	mm	meter
1569275, 1569271, 1569274, 1569273, 1568186, 1569270, 1565890, 1569272	CBBOX0205	3	2 ~ 5	10
1564739, 1568180, 1568184, 1568182, 1568187, 1570435, 1572560, 1570437	CBBOX0307	5	3 ~ 7	10
1571652, 1571636, 1571645, 1571650, 1572523, 1572561, 1572535, 1572541	CBBOX0408	6	4 ~ 8	10
1572554, 1572545, 1572549, 1572548, 1572524, 1571639, 1572530, 1572542, 1572562	CBBOX0510	8	5 ~ 10	10
1572555, 1572531, 1572543, 1571635, 1572563, 1572536, 1571646, 1572550	CBBOX0612	10	6 ~ 12	10
1572556, 1571637, 1571641, 1572551, 1572525, 1571654, 1572537	CBBOX0814	13	8 ~ 14	10
1571653, 1572532, 1572546, 1572544, 1571649, 1572526, 1572564, 1572538	CBBOX1015	14	10 ~ 15	10
1572557, 1572533, 1571647, 1571642, 1572552, 1572527, 1571655, 1571640	CBBOX1221	16	12 ~ 21	10
1572558, 1571638, 1571648, 1571643, 1572553, 1571656, 1572528, 1572565, 1572539	CBBOX1527	17	15 ~ 27	10
1572559, 1572534, 1572547, 1572566, 1571644, 1572529, 1572540	CBBOX2028	18	20 ~ 28	5
1568189, 1568181, 1570439, 1568183, 1564738, 1570436, 1570440, 1570438	CBBOX2534	25	25 ~ 34	5
1565451, 1565449, 1568185, 1564737, 1568188, 1568190, 1568179, 1565450	CBBOX3037	30	30 ~ 37	5

Specifications:

Material : PET
 Flammability : VW-1
 Working temperature : -40°C ~ 150°C
 Melting temperature : 250°C ± 5