


# Data Sheet

## FLRY-A Cable 0.35 mm<sup>2</sup>

Version 01/21

Item no.: 1568628	Blue	Item no.: 1568632	Yellow
Item no.: 1568629	Black	Item no.: 1568633	Green
Item no.: 1565597	Red	Item no.: 1568634	Grey
Item no.: 1565598	Orange	Item no.: 1568635	Pink
Item no.: 1568630	Brown	Item no.: 1568636	Violet
Item no.: 1568631	White		

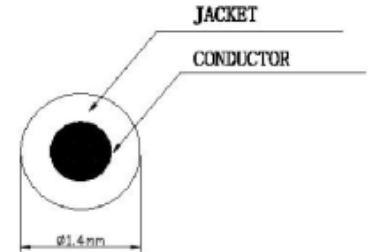

Jacket, outer dimension.....	PVC 1.3mm
No. of conductors.....	7 x 0.26mm
Strand per conductor.....	0.35 mm <sup>2</sup>
Length.....	50 meter
Conductor material .....	copper
Insulation material (with thickness).....	PVC 0.3mm
Core diameter.....	0.7mm
Insulation resistance.....	Min 200M ohm x km
Maximum dielectric strength.....	800V / AC
Temperature range.....	-40 to +105 °C
Rated voltage.....	< DC75 V / AC50 V
Resistance.....	52 mohm/M (20 °C)
Halogen-free.....	N
Lead-free.....	Y
Weight.....	4.47 kg/km