


## Data Sheet

---

### FLRY-A Cable 0.5mm<sup>2</sup>

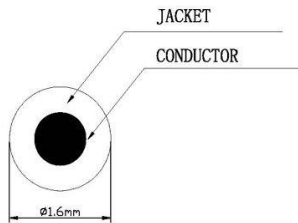

#### Technical data:

Jacket, outer dimension.....	PVC 1.6mm
No. of conductors.....	19 x 0.19mm
Strand per conductor.....	0.5 mm <sup>2</sup>
Color.....	Red
Length.....	50 meters
Conductor material .....	copper
Insulation material (with thickness).....	PVC 0.37mm
Core diameter.....	0.85mm
Insulation resistance.....	Min 200M ohm x km
Maximum dielectric strength.....	800V / AC
Temperature range.....	-20 to +105 °C
Rated voltage.....	12/24V