


Data Sheet

RoHS HI-REL IC socket, Gold/Tin, Pin:17.8mm



Drawing:

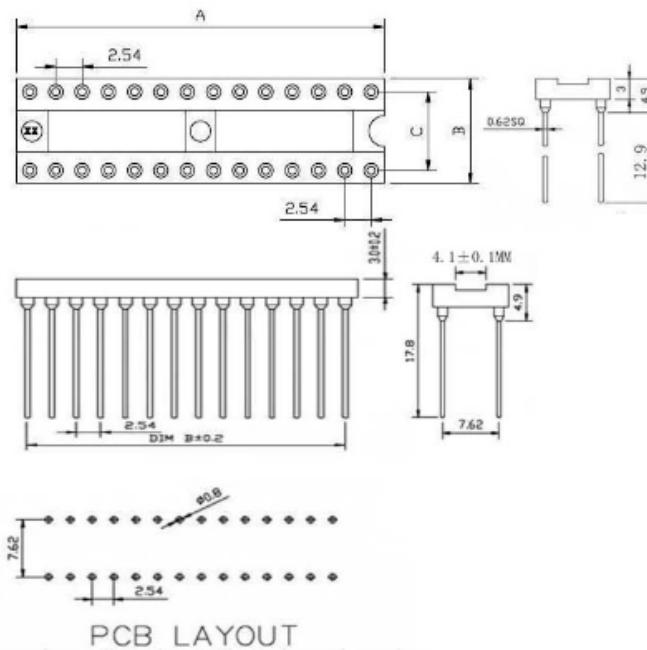

BN	No. of pins	A	B	C
1565630	14	15.24	10.16	7.62
1568712	20	22.86	10.16	7.62

Data Sheet

Technical data

Current rating: 3 Amp

Insulation resistance: 1000 mΩ min

Contact resistance: 20 mΩ

Withstanding voltage: AC 500 V min

Operating temperature: -40 °C ~ +105 °C

Contact material: Copper Alloy and Gold Flash

Insulation material: Polyester. UL94-0 PBT

Colour: Black

General Tolerance: x. ± 0.30

x.x ± 0.25

x.xx ± 0.15