


Datasheet

Item no. 1569029

V1_07312018_01_en

Standard TEC module, 30x30x3.6mm

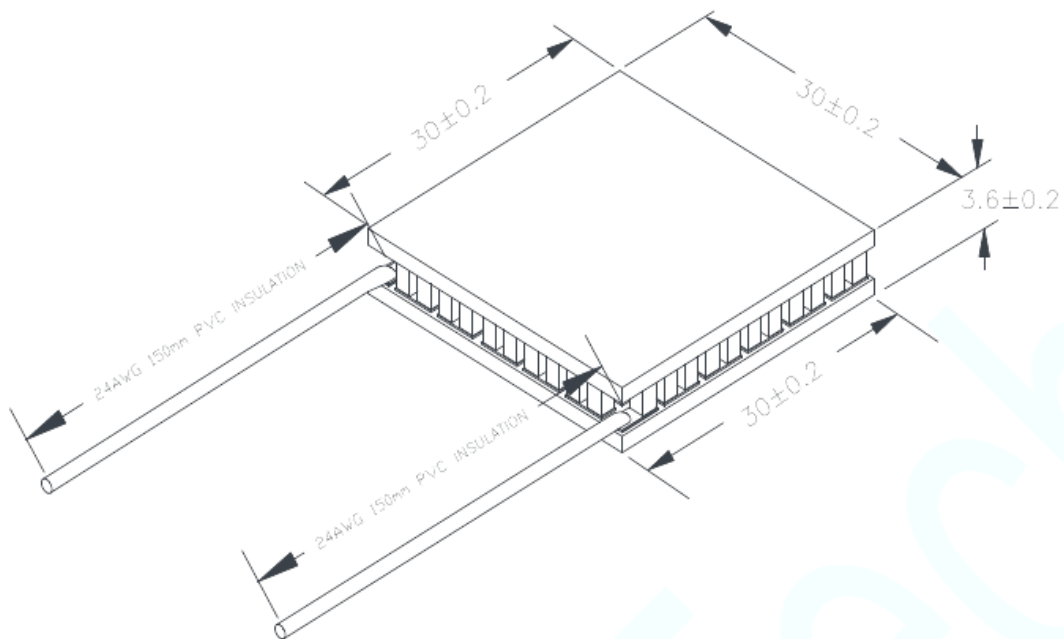

Max Operating Temperature: 90°C.

Hot Side Temperature(°C)	25 °C	50 °C
Qmax (Watts)	25.7	29.8
Delta Tmax(°C)	67	75
I _{max} (Amps)	3	3
V _{max} (Volts)	15.4	16.4
Module Resistance(Ohms)	4.16	4.69


**Tolerances for thermal and electrical parameters ± 10%.

Datasheet

Item no. 1569029

V1_07312018_01_en

Performance Curves Th=25 °C

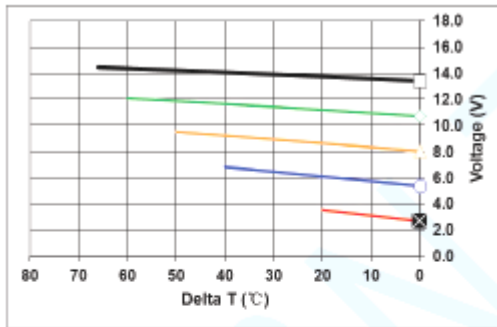

Performance Curves Th=50 °C

