
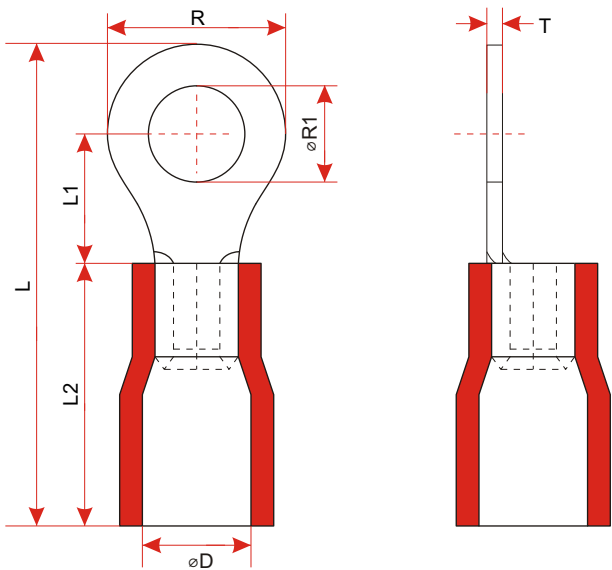


Data Sheet

Insulated Crimp Ring Terminal Connector Set,
100pcs

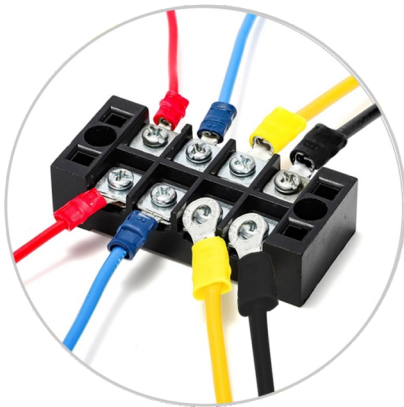

Specification

Color: Red
Insulator Material: Vinyl(PVC)
Terminal Material: Tin-Plated Copper
Working Temperature: 75°C max.
Rating Voltage: 300V/AC max.
Rating Current: 9Amp.max.

BN	Wire RANGE mm ² / AWG	Dimension(mm)							Stud Size	Quantity	Color
		L	L1	L2	ϕD	T	R	ϕR1			
1572134	0.5-1.5 mm ² 22-16 AWG	18.0±1.5	5.0±0.5	10.0±0.5	4.0±0.3	0.65±0.5	5.6±0.3	3.2±0.2	M3	100	Red
1564455		20.1±1.5	6.3±0.5	10.0±0.5	4.0±0.3	0.55±0.5	6.6±0.3	4.3±0.2	M4	100	
1570153		21.5±1.5	7.0±0.5	10.0±0.5	4.0±0.3	0.55±0.5	8.0±0.3	5.2±0.2	M5	100	
1572135		23.5±1.5	8.5±0.5	10.0±0.5	4.0±0.3	0.67±0.5	9.8±0.3	6.4±0.2	M6	100	
1566746		25.5±1.5	9.4±0.5	10.0±0.5	4.0±0.3	0.56±0.5	11.6±0.3	8.4±0.2	M8	100	
1566943		31.1±1.5	13.9±0.5	10.0±0.5	4.0±0.3	0.60±0.5	13.6±0.3	10.5±0.2	M10	100	