


Data Sheet

Rev. 2

Length	B/N	B/N	B/N	B/N	B/N	B/N	B/N	B/N	B/N	B/N
10 M	1565154	1566830	1566831	1566832	1566848	1565155	1570172	1564475	1566833	1566834
25 M	1571380	1566876	1571381	1571382	1564485	1570694	1570173	1571383	1570576	1570908
100 M	1570577	1570174	1566835	1566836	1566837	1570175	1566849	1570178	1570696	1566850
Color	Red	Black	Blue	Yellow	Brown	Green	Grey	Orange	White	Violet

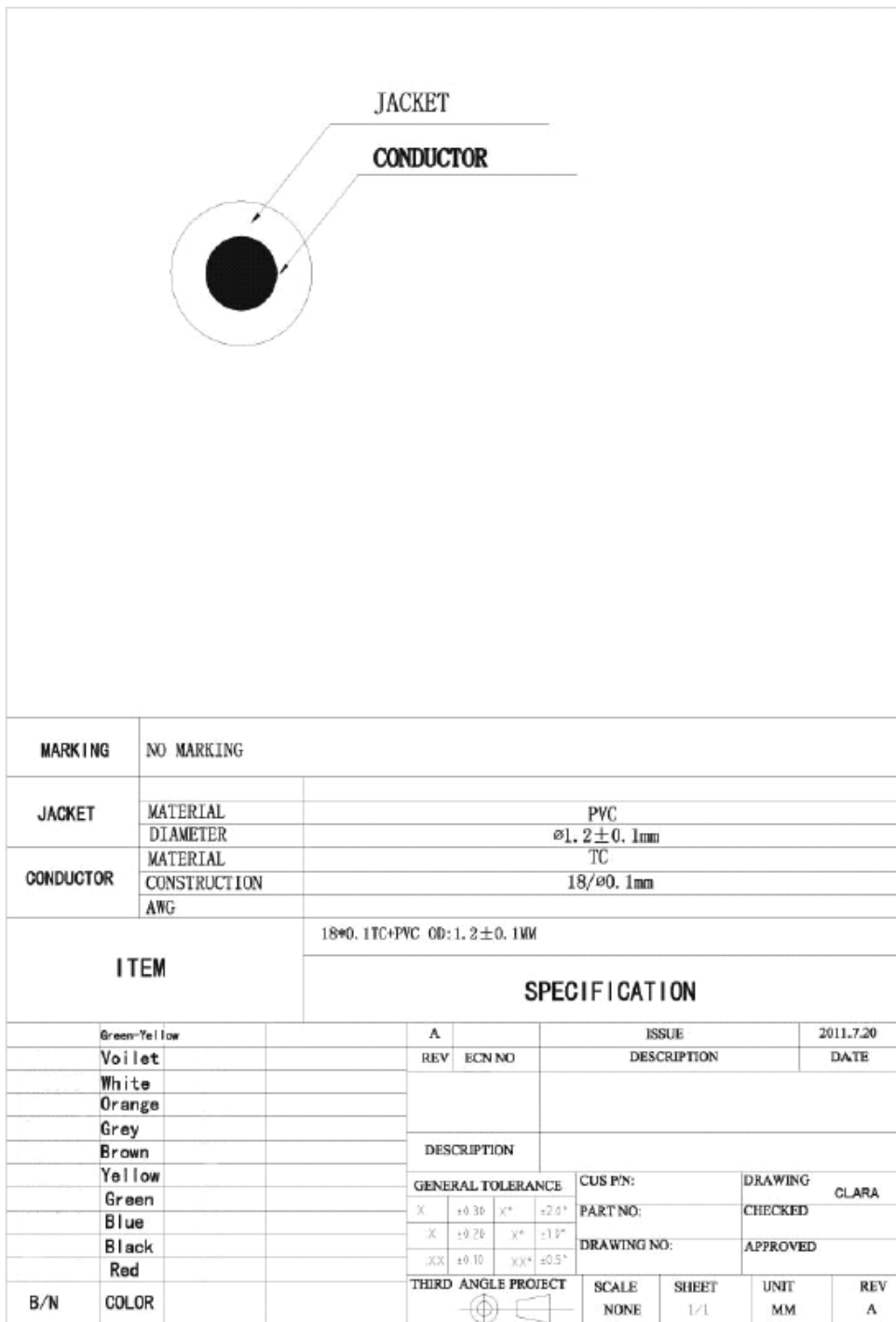

Data Sheet

Rev.2

Jacket, Outer Dimension	PVC 1.2 mm
No. of conductors	18 x 0.1 mm
strand per conductor	0.14 mm ²
Material	Tinned Copper
Insulation material (with thickness)	PVC 0.38 mm
Core diameter	0.1 mm
Conductor resistance (Ω /km)	Max. 145 Ω /km
Insulation resistance	Min. 200 Ω x km
Max. dielectric strength	1500V/ AC
Temperature range	-20 to 70°C
Rated voltage	48V
Conductor structure	Twisted