


Datasheet

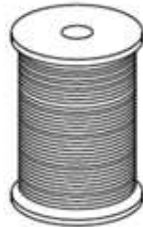

Specification

Copper Wire
Enamel
Temperature



2UEWF
PU class 155
155°C max.

Enameled Copper Wire

b/n	Wire Diameter (mm)	Meter	Enamel/ PU Coating Thickness (mm)	Resistance (Ω/km)	Rated Voltage (kv)
1570224	0.05 ± 0.015	1500	0.008-0.019	10240	0.30
1570225	0.1 ± 0.018	450	0.01-0.025	2381	0.50
1567045	0.15 ± 0.02	220	0.012-0.027	1037	1.00
1567046	0.2 ± 0.023	110	0.016-0.031	577.2	1.50
1567047	0.3 ± 0.04	50	0.02-0.037	254	2.00
1567048	0.4 ± 0.05	35	0.022-0.039	141.7	2.20
1567049	0.5 ± 0.065	23	0.024-0.42	89.95	2.50
1565202	0.8 ± 0.085	9	0.03-0.052	35.17	2.80
1567050	1 ± 0.1	6	0.034-0.062	22.49	3.00