


Item no.: 1570264

Data Sheet

Fuse 10 A/1000 V flux 10.3 mm x 38 mm



Drawing:

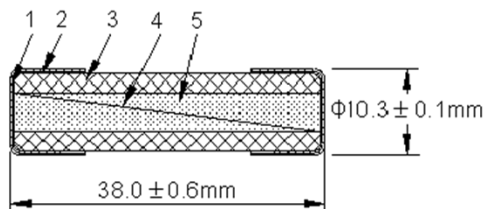

Technical data

Standard: IEC 60269-4, GB 13539.4, UL248-13.

Voltage: 1000 V AC/DC

Current: 250 mA-20 A

Class of operation: aR

Breaking capacity: 50 kA @1000 V AC, 30 kA @1000 V DC

Operating temperature: $-40 \text{ }^{\circ}\text{C} \sim +125 \text{ }^{\circ}\text{C}$

Storage temperature: $-40 \text{ }^{\circ}\text{C} \sim +90 \text{ }^{\circ}\text{C}$

Data Sheet

The Average I-T Characteristics Curve

