


Datasheet

Item no. 1569025

V1_0917_01_en

Mini Solar cell panel, rectangular, 18 x 30 mm

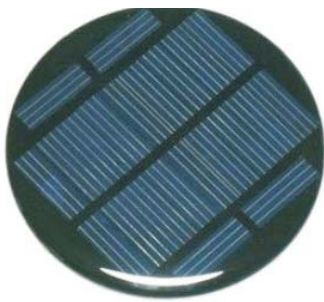

Item no.	Dimension (±0.3)	Thickness (±0.3)	SolarcellType	Maximum Power(P.max)	Power Tolerance	RatedVoltage (V.mp)	Rated Current(Imp)	OpenCircuit Voltage(Voc)	ShortCircuit Current(Isc)	NetWeight Approx.
1572739	Φ56mm	2.7mm	Polycrystalline	0.2W	±5%	2V	0.1A	2.4V	0.105A	0.008kg
1565764	Φ70mm	2.9mm	Polycrystalline	0.24W	±5%	2V	0.12A	2.4V	0.126A	0.014kg
1569022	49x49mm	3.1mm	Polycrystalline	0.2W	±5%	2V	0.1A	2.4V	0.055A	0.01kg
1569023	55x55mm	3.1mm	Polycrystalline	0.23W	±5%	2.5V	0.09A	3V	0.092A	0.011kg
1572740	80x80mm	3.1mm	Polycrystalline	0.8W	±5%	2V	0.4A	2.4V	0.42A	0.033kg
1565765	80x80mm	3.1mm	Polycrystalline	0.8W	±5%	4V	0.2A	4.8V	0.21A	0.031kg
1569024	80x80mm	2.9mm	Polycrystalline	0.6W	±5%	5V	0.12A	6V	0.126A	0.031kg
1569025	18x30mm	3.1mm	Polycrystalline	0.04W	±5%	0.5V	0.08A	0.52V	0.165A	0.004kg
1564741	30x60mm	2.7mm	Polycrystalline	0.1W	±5%	2V	0.05A	2.4V	0.053A	0.005kg
1565766	30x70mm	2.7mm	Polycrystalline	0.2W	±5%	5V	0.04A	2.4V	0.042A	0.007kg
1570491	30x90mm	2.7mm	Polycrystalline	0.3W	±5%	6V	0.05A	7.2V	0.053A	0.01kg
1569026	59.5x62.5mm	3.1mm	Polycrystalline	0.04W	±5%	5V	0.08A	5.5V	0.01A	0.012kg
1564742	20x106mm	3.1mm	Polycrystalline	0.13W	±5%	2V	0.065A	2.2V	0.036A	0.015kg
1569027	60x100mm	2.8mm	Polycrystalline	0.72W	±5%	6V	0.12A	7.2V	0.126A	0.02kg

Operating Temperature	-20°c~80°c
Storage Temperature	10°c~65°c
OperatingHumidity	25%~95%RH
Storage Humidity	15%~75%RH

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com).

All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represents the technical status at the time of printing.

© Copyright 2017 by Conrad Electronic SE.