


## Data Sheet

### Limit Switch

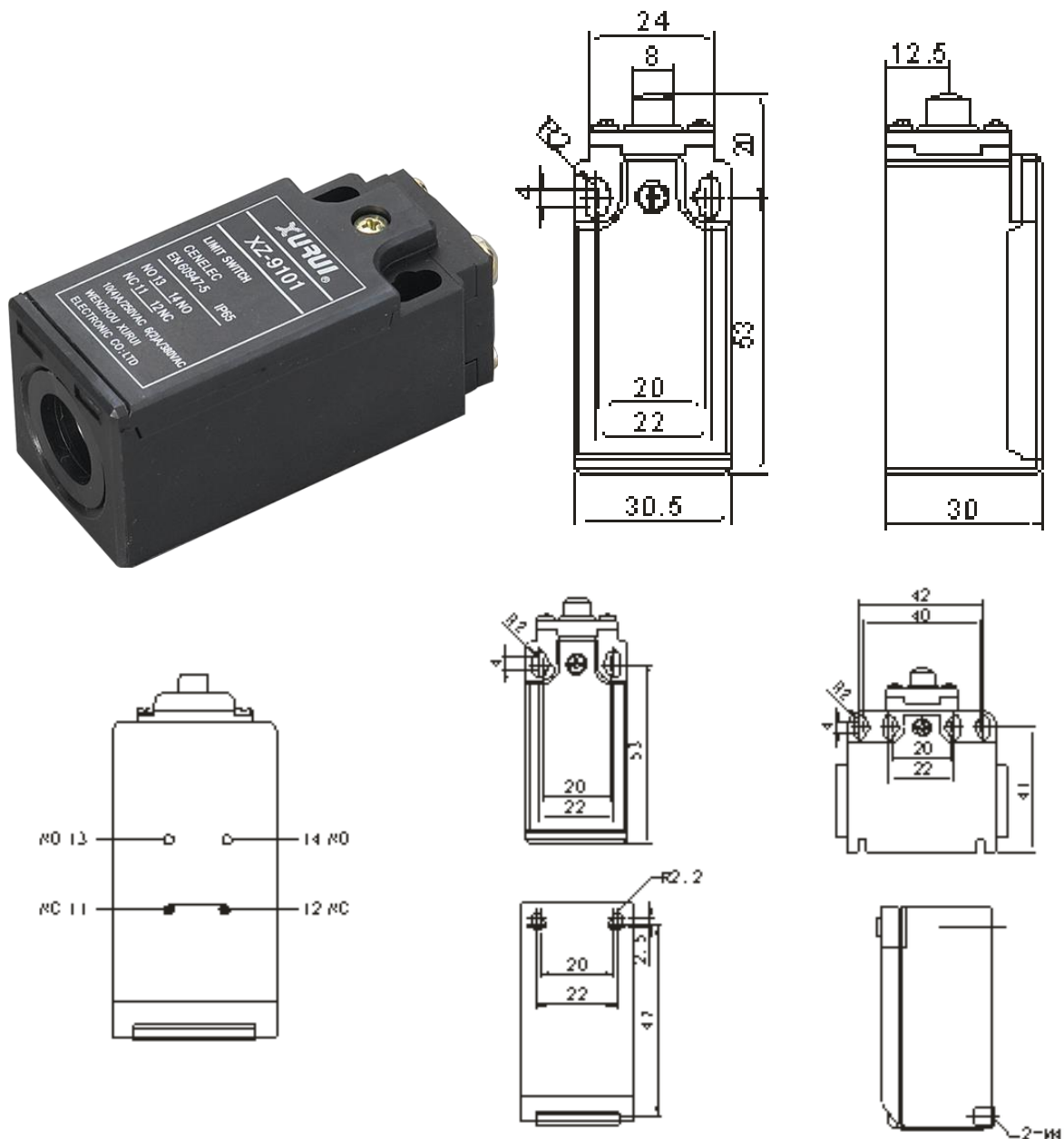

## Data Sheet

---

### Technical data

- 1 Housing Material: Thermoplastic cover
- 2 Contact material and plating: silver contact
- 3 Tolerance (Tolerance standard GB/T1804-m): >6-30/±0.2; >30-120±0.3
- 4 Rating loads: 10(4)A/250VAC,6(2)A 380VAC
- 5 Operation speed: 5mm-0.5m/s
- 6 Insulation resistance: ≥100MΩ(above)DC500V
- 7 Contact resistance: 25mΩ (initial value)
- 8 Withstand voltage of Non-connection wire: 1000VAC
- 9 Withstand voltage of Every terminal: 1500VAC
- 10 Vibration Misoperation: 10-55Hz Amplitude 1.5mm
- 11 Actuator type: Button type
- 12 Electrical life: 100,000 above
- 13 Mechanical life: 1,000,000 above
- 14 Operating temperature: -10 ~ 70 Celsius degrees.
- 15 Operating humidity: < 85 %
- 16 Mechanical operation frequency: 120 times/min
- 17 Electrical operation frequency: 30 times/min