



DATASHEET

Alligator clip set, 30 pcs, 3 sizes, 5 colors


Item No. 1570584

Overview



Technical data

Material.....	Steel
Insulation material	PVC
Soldering method	Heating
Plated material.....	Nickel
Rated voltage	< 50 V AC / 75 V DC
Operating temperature	-20 to +70 °C
Operating humidity	35 - 95 % RH
Storage temperature.....	-20 to +70 °C
Storage humidity.....	35 - 95 % RH
Color.....	Red / Black / White / Yellow / Green
	Small: 2 each (10 pcs)
	Medium: 2 each (10 pcs)
	Large: 2 each (10 pcs)
Weight	75 g (bulk pack)

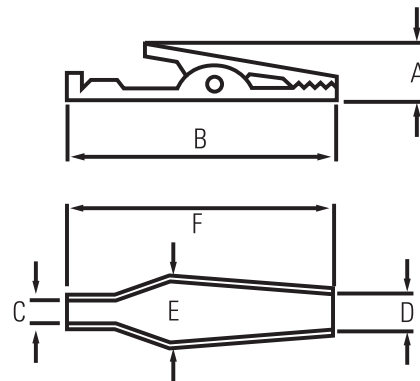

Size	Length	Current	A	B	C	D	E	F
Small	27 mm	2 A	8.9 ± 0.5	27 ± 0.5	3.5 ± 0.5	6.5 ± 0.5	10.3 ± 0.5	33 ± 0.5
Medium	35 mm	3 A	8.3 ± 0.5	35 ± 0.5	3.5 ± 0.5	7 ± 0.5	11 ± 0.5	38.5 ± 0.5
Large	44 mm	5 A	12.4 ± 0.5	44 ± 0.5	3.5 ± 0.5	9 ± 0.5	15 ± 0.5	48 ± 0.5

Measurements in mm