


Data Sheet

Pre-fab braid

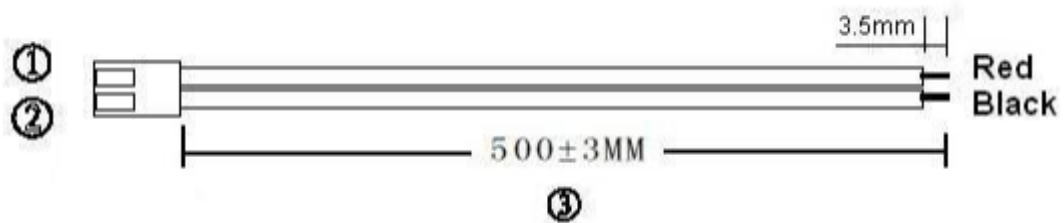

1. Wire: UL 1007 26# Soldered 3.5mm/ dupont 2.5-2P
2. HG
3. TE

Cable length~ 50 cm, free end~ bared and tin-plated 3mm

Connector type	Socket, straight
Connectors	wire-to-board
CS	2.54 mm
Pins per row	2

Data Sheet

Total number of pins	2
Content	1 pc(s)
Colour	Red , Black
Length	500 mm
Compatible with (details)	26
Industrial packaging	No
Connection	Open end cable
Nominal voltage	45 V AC
AWG max.	26
AWG (min.)	26
Insulation material	PVC
No. of rows	1
Cross section	0.14 mm ²
AWG	26
Contact material	Copper alloy
Case material	PBT
RoHS-compliant	Yes
Max. temperature	80 °C