


Polybag, Plain Type, 80 x 120 mm

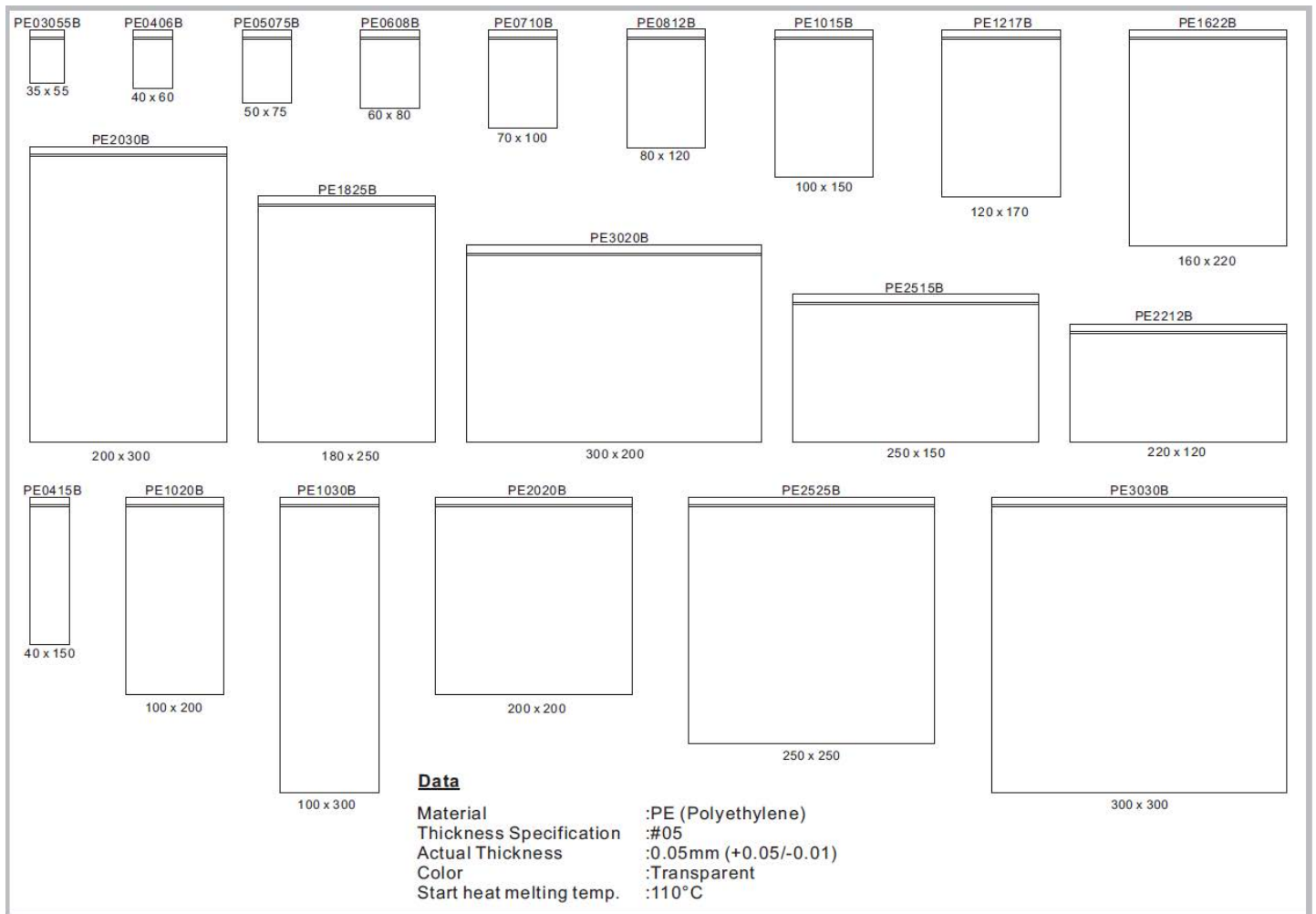

Part Number	Dimensions (mm)
PE03055B	35 x 55
PE0406B	40 x 60
PE05075B	50 x 75
PE0608B	60 x 80
PE0710B	70 x 100
PE0812B	80 x 120
PE1015B	100 x 150
PE1217B	120 x 170
PE1622B	160 x 220
PE2030B	200 x 300
PE1825B	180 x 250
PE3020B	300 x 200
PE2515B	250 x 150
PE2212B	220 x 120
PE0415B	40 x 150
PE1020B	100 x 200
PE1030B	100 x 300
PE2020B	200 x 200
PE2525B	250 x 250
PE3030B	300 x 300

Data

Material	:PE (Polyethylene)
Thickness Specification	:#05
Actual Thickness	:0.05mm (+0.05/-0.01)
Color	:Transparent
Start heat melting temp.	:110°C

Unit: mm

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com).

All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represents the technical status at the time of printing.

© Copyright 2017 by Conrad Electronic SE.