
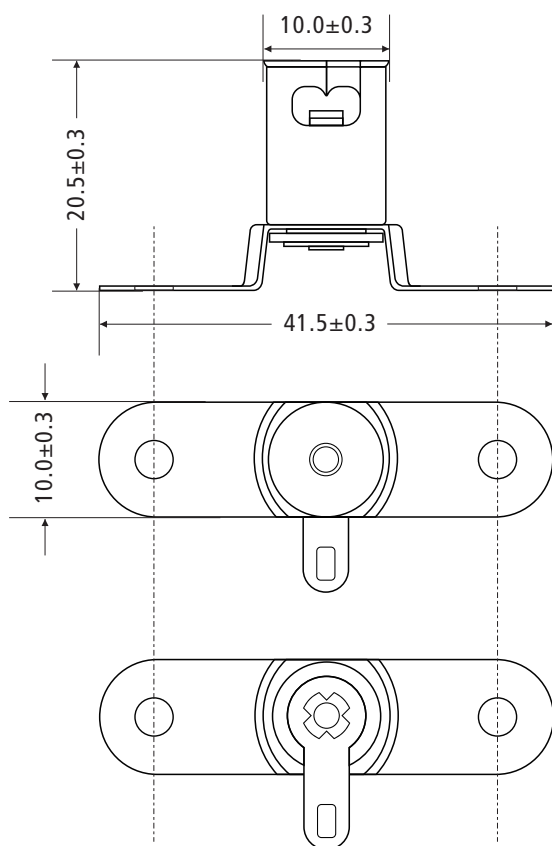


BA9s Lamp Bulb Socket

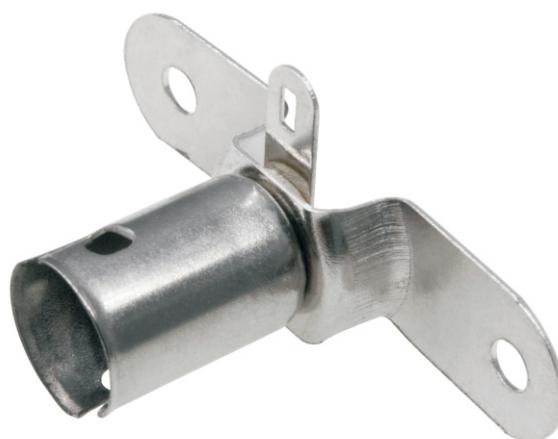

Specification

Lamp bulb type: BA9s
 Material: Brass
 Plating: Nickel
 Voltage rating: 24V (DC)
 Current rating: 3A max.
 Operating temperature: -10 to 105°C
 Operation humidity: >85%RH
 Storage temperature: -10 to 85°C
 Operation humidity: >95%RH