


IEC C5 power plug cable

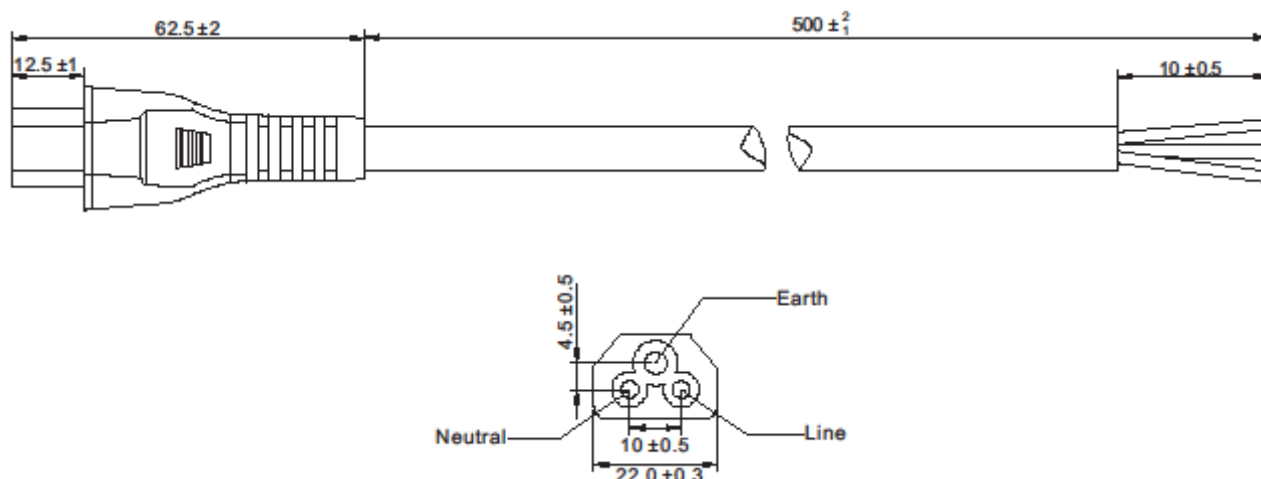

Voltage Rating:	250V/ AC
Current Rating:	2.5 A
High Voltage Test:	2kv/ 1 minute
Insulating Resistance:	>500MΩ/ 1 minute
Cable Standard:	3 x 0.75 mm ²
Conductive Construction:	42 x 0.15 mm (±0.004)
External Diameter:	7.0 mm ±0.2
Operating Temperature:	-20°C to 105°C