


## RJ45 Tooless Plug – Standard Installation guide

1. Remove the stopper cover before installation

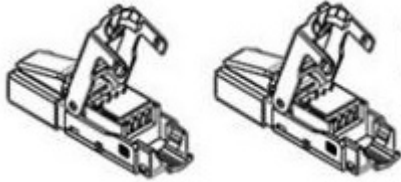

Color coding	T568A	T568B
1	White/Green	White/Orange
2	Green	Orange
3	White/Orange	White/Green
6	Orange	Green
4	Blue	Blue
5	White/Blue	White/Blue
7	White/Brown	White/Brown
8	Brown	Brown

2. Insert cable into Strain relief boot, strip off 30mm of cable jacket and then fold back the drain wire




Adjust the dia. of boot: Cut the end of the boot to fit your cable O.D




3. Fan out all four twisted pair wires, following 568-B color coding label and allocate each wire into proper slots on wiring cap. Trim the ends of wires

T568-B color code:  
Four wires down side (left->right);  
WH/GN,GN,BR,WH/BR


T568-A color code:  
Four wires upper side (left->right);  
WH/OR,OR,WH/BL,BL

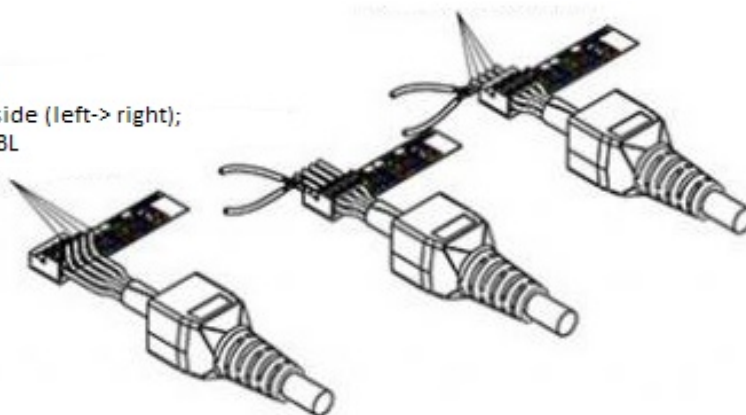


4. Remove the wiring label before place wiring cap on plug

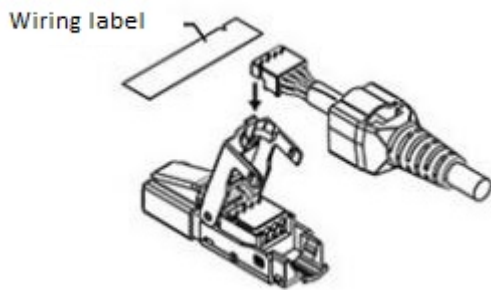

5. Place the wiring cap onto plug, use plier to clamp wiring cap until it is completely snap-in to effect the connection

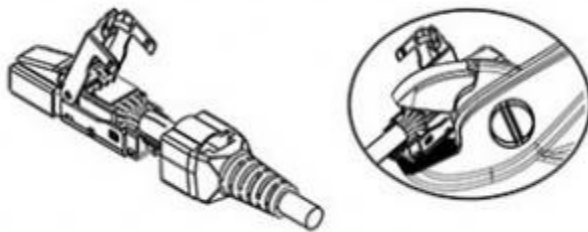

6. Close plug cover, make sure the drain wire is in proper contact with grounding clip. Pull back strain relief boot to cover the plug, fasten nylon cable tie to secure grounding contact.

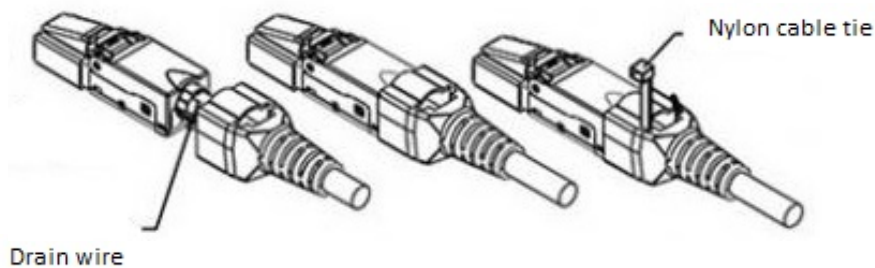

7. Unload the cable:

Cut off cable tie, remove the boot. Using flat screw driver and pry gently on plug cover one end first and the other end subsequently to open it

