
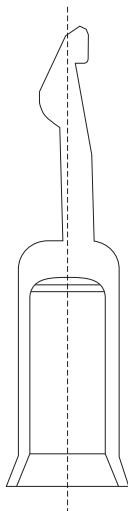


Data Sheet

Crimp Contacts for 50A / 75 A Battery Connector Cable Cross-section: 13.3 mm²

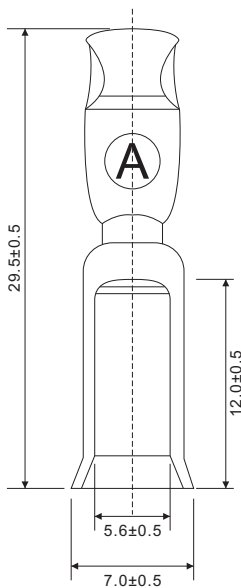

Product Specifications

Contact material: Copper/Plating Silver

Rated Current(Ampere): 75A max.

Rated Voltage(Voltage) : 600V

Contact Barrel Wire Size(AWG) : 6AWG(13.3mm²)

Average contact resistance : 0.05MΩ

Operating temperature range: -20°C to 125°C