


Single Conductor Flexible cable

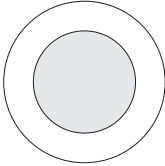

Technical & Specification

Cross-section	0.08mm ²
External Dia.	ø1mm ±0.1
Construction	16 x ø0.08mm
Material:	
Conductor	Tined Copper
Insulator	PVC
Jacket Color	Black/White/Blue/Brown/ Red/Yellow/Green/ Grey/Orange/Purple
Dielectric strength	0.5kv/ 1 minute
Rated voltage	75VDC / 50VAC
Max. Load capacity	0.48A (reference only)
Conductor Resistance	248Ω/KM at 20°C
Insulator Resistance	15MΩ/KM at 20°C
Flame Class	94V-2
Operating Temperature	-10 ~ 70°C
Storage Temperature	-20 ~ 80°C