


Data Sheet

224 pcs Assortment Ceramic Capacitor Set

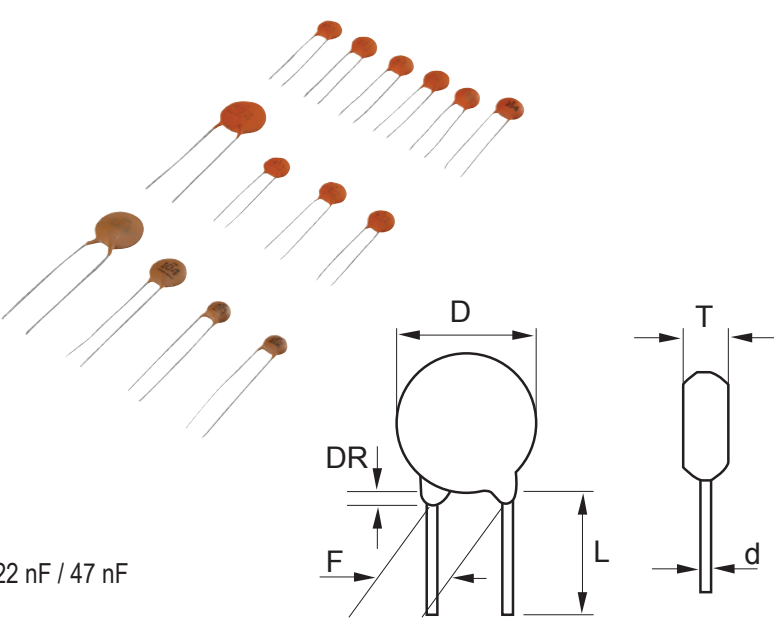

21 pcs: 10 pF / 100 pF / 1 nF / 10nF / 100 nF
14 pcs: 22 pF / 47 pF / 220 pF / 470 pF / 2.2 nF / 4.7 nF / 22 nF / 47 nF
7 pcs: 220 nF

Item	Tolerance	Specification	Electrical performance			Dimension(mm)					
			Cap(PF)	DF(%)	IR(MΩ)	T.V(DC)	D±0.5	T±0.5	F±0.5	L±2	d±0.05
1	±10%	10PF50V	9-11	≤2.5	≥3000	50V	4.5	2	2.5	18	0.4
2	80-20%	2.2NF50V	1760-3960	≤5	≥3000	50V	4.5	2	2.5	18	0.4
3	80-20%	4.7NF50V	3760-8460	≤5	≥3000	50V	4.5	2	2.5	18	0.4
4	80-20%	22NF50V	17600-39600	≤6	≥100	50V	4.5	2	2.5	18	0.4
5	80-20%	47NF50V	37600-84600	≤6	≥100	50V	4.5	2	2.5	18	0.4
6	±10%	100PF50V	90-110	≤2.5	≥3000	50V	4.5	2	2.5	18	0.4
7	±20%	1NF50V	800-1200	≤2.5	≥3000	50V	4.5	2	2.5	18	0.4
8	80-20%	10NF50V	8000-18000	≤5	≥3000	50V	5.0	2	2.5	18	0.4
9	±20%	100NF50V	80000-120000	≤6	≥100	50V	5.5	2	2.5	18	0.4
10	±10%	22PF50V	19.8-24.2	≤2.5	≥3000	50V	4.5	2	2.5	18	0.4
11	±10%	47PF50V	42.3-51.7	≤2.5	≥3000	50V	4.5	2	2.5	18	0.4
12	±10%	220PF50V	198-242	≤2.5	≥3000	50V	4.5	2	2.5	18	0.4
13	±10%	470PF50V	423-517	≤2.5	≥3000	50V	4.5	2	2.5	18	0.4
14	80-20%	220NF50V	176000-396000	≤6	≥100	50V	8.0	2	2.5	18	0.45