


Data Sheet

Indicator Light, dual colour, red / green, 12 Volt

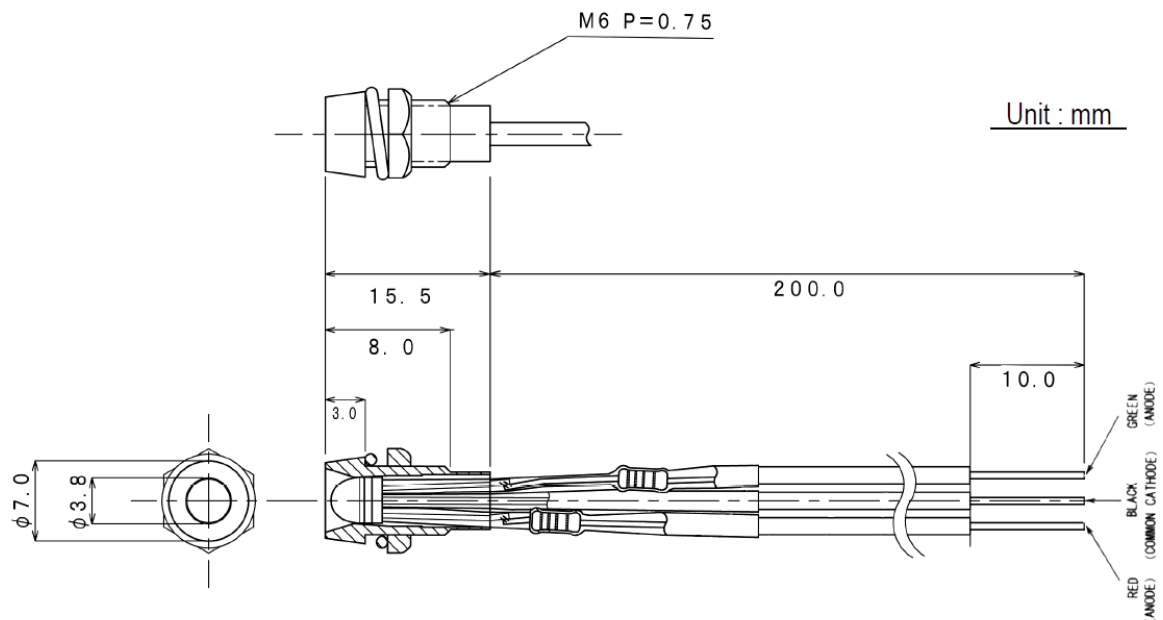

DATA	
Material of Body	chrome plated brass
Color (LED)	red, green
Lens	white
Voltage	12 V
Voltage Breakdown	AC 500 V / minute
Insulation Resistance	DC 500 V 100M Ω or more
Protecting Resistor	680 Ω
Operating Temperature	-20 to +75°C
Terminals	lead wires (UL1007 AWG24)
Thread	$\phi 6.00$ mm X L 8.0 mm pitch = 0.75 mm
Mounting Hole (Recommended)	$\phi 6.2$ mm