


Data Sheet

Bullet connector (pre-fab) plug

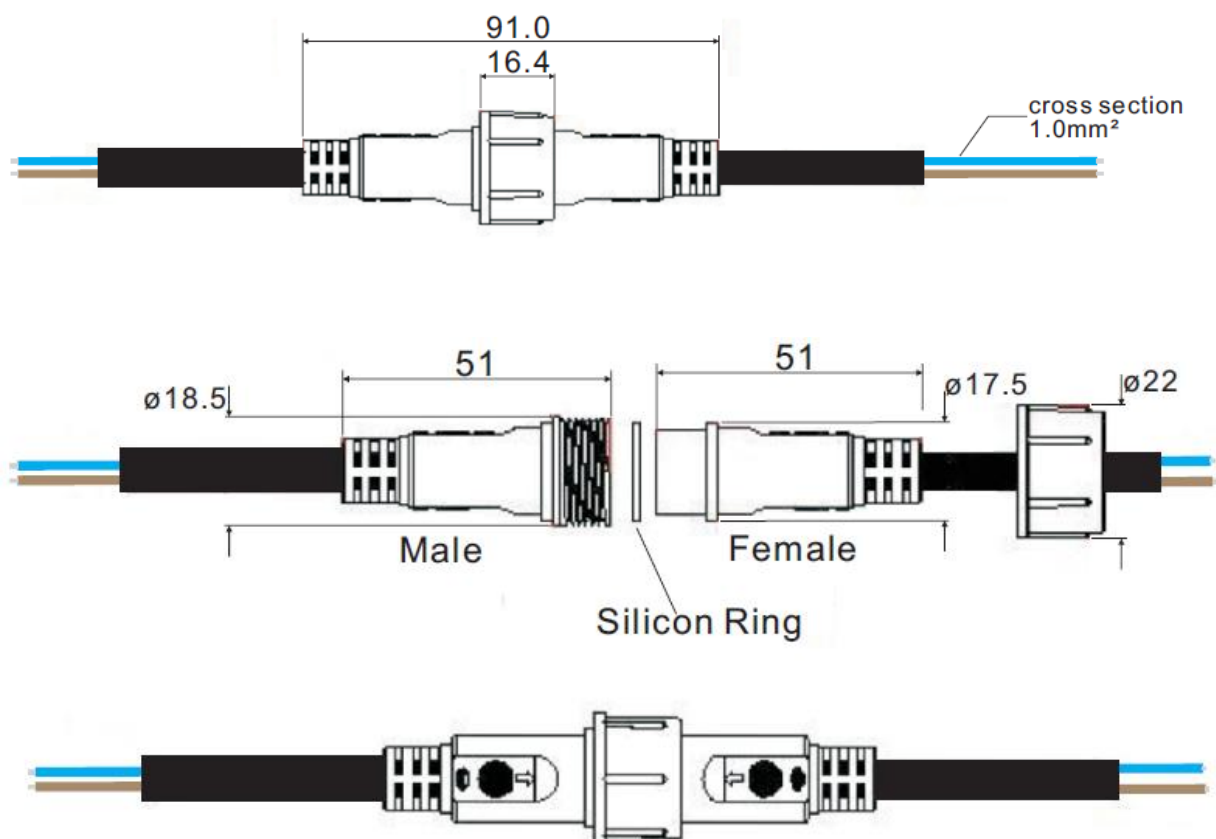

Data Sheet

Technical information:

Cable: male 500mm/ female 500mm

Contact pole: 2

Nominal current: 10A max

Voltage rating: 50VAC max./ 75VDC max.

Breakdown voltage: >1.5kv/ 1min

Cross section range: 1mm² (max.)

Connection angle: 180°C

Operation temperature: -40°C ~ 105°C

Material:

Connector body: PVC

Cable insulation: rubber

Sealing O-Ring: silicon

Contact pin: copper alloy

Waterproof class: IP68