


## Data Sheet

---

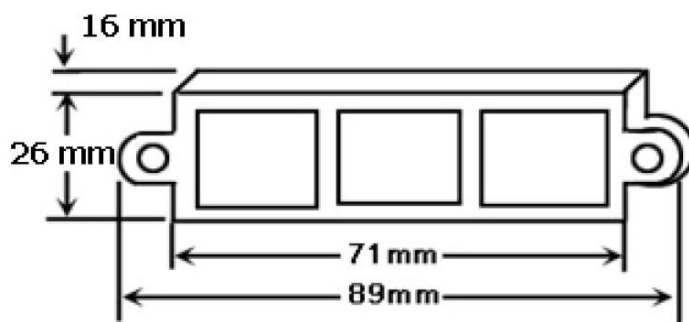

Voltage: 12 V/DC

Resistance: 1.9 – 4.8  $\Omega$

Current: 5 – 6.6 A

Power (max.): 60 W – 80 W

Surface temperature (max.): 100 - 130°C

Plastic frame (PPS) temperature (max.): 300°C

Connection: Plug-in cable lugs with a width of 4.8 mm

Material: Semiconductive Ceramic, PPS, Stainless steel