


Polybag, Plain Type, 100 x 300 mm

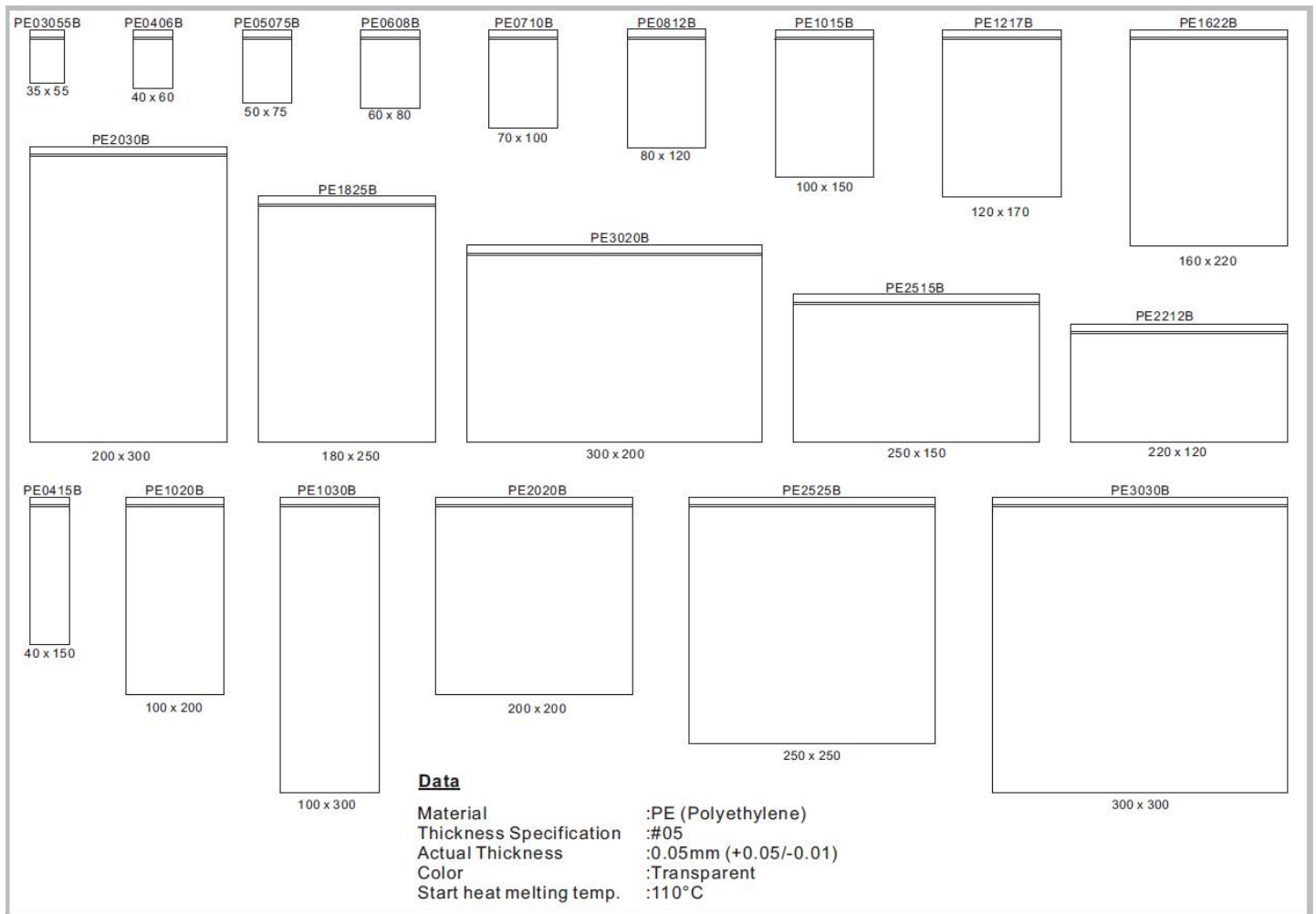

The diagram illustrates 20 different sizes of polybags, each represented by a rectangle with its dimensions and a part number. The sizes are as follows:

- PE03055B: 35 x 55
- PE0406B: 40 x 60
- PE05075B: 50 x 75
- PE0608B: 60 x 80
- PE0710B: 70 x 100
- PE0812B: 80 x 120
- PE1015B: 100 x 150
- PE1217B: 120 x 170
- PE1622B: 160 x 220
- PE2030B: 200 x 300
- PE1825B: 180 x 250
- PE3020B: 300 x 200
- PE2515B: 250 x 150
- PE2212B: 220 x 120
- PE0415B: 40 x 150
- PE1020B: 100 x 200
- PE1030B: 100 x 300
- PE2020B: 200 x 200
- PE2525B: 250 x 250
- PE3030B: 300 x 300

Data

Material	:PE (Polyethylene)
Thickness Specification	:#05
Actual Thickness	:0.05mm (+0.05/-0.01)
Color	:Transparent
Start heat melting temp.	:110°C

Unit: mm

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com).

All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represents the technical status at the time of printing.

© Copyright 2017 by Conrad Electronic SE.