


## Fuse lamp 8V/DC 0.15A

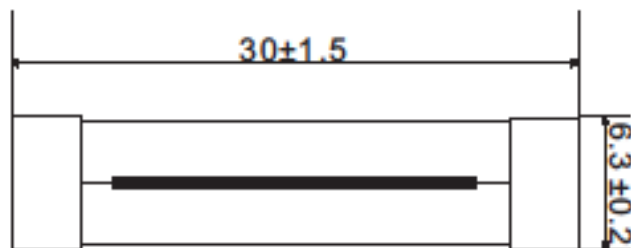

Glass shell .....	$\varnothing 6.0\text{mm} \pm 0.2$	
Foot type .....	ST6	
Foam body .....	$30\text{mm} \pm 1.5$	
Tungsten filament .....	C-8	
Voltage rating .....	8V/ DC	
Current rating .....	$150\text{mA} \pm 10\%$	
Output power .....	$1.2\text{W} \pm 10\%$	
Flux .....	$3.6\text{Lm} \pm 25\%$	
Average life .....	1000hrs	
Lowest life .....	50% of average life	Unit: mm

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau ([www.conrad.com](http://www.conrad.com)).  
 All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represents the technical status at the time of printing.