


# Datasheet

Item no. 1572703 (4 Pin) 1572704 (6 Pin) 1572705 (8 Pin)  
 1571705 (10 Pin) 1568704 (14 Pin) 1568705(16 Pin)  
 1572706 (18 Pin) 1571706 (20 Pin) 1565627 (22 Pin)  
 1572707 (24 Pin) 1568706 (28 Pin)

V1\_07262018\_01\_en

## IC Socket 7.62mm, Pin 7.43mm

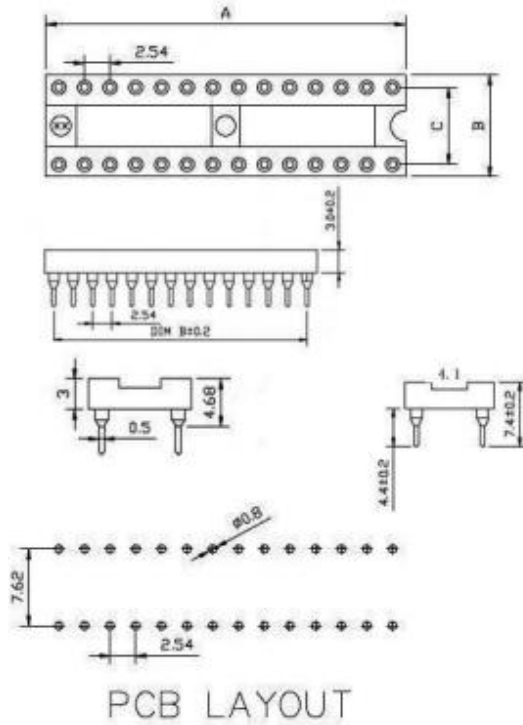

No. of pins	A	B	C	model no.
4	5.08	10.16	7.62	303-040
6	7.62	10.16	7.62	303-060
8	10.16	10.16	7.62	303-080
10	12.70	10.16	7.62	303-100
14	15.24	10.16	7.62	303-140
16	17.78	10.16	7.62	303-160
18	20.32	10.16	7.62	303-180
20	22.86	10.16	7.62	303-200
22	28.05	10.16	7.62	303-220
24	30.48	10.16	7.62	303-240
28	35.60	10.16	7.62	303-280

Current Rating:	3Amp
Insulating Resistance:	1000MΩ min
Contact Resistance	20m Ω
Withstanding Voltage:	AC 500V min
Operating Temperature:	-40°C to +105°C
Contact Material:	Copper Alloy and Gold Flash
Insulation Material:	Polyester. UL94-0 PBT
Colour:	Black
General Tolerance:	x. ±0.30 x.x ±0.25 x.xx ±0.15