
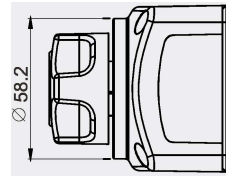



# 019052

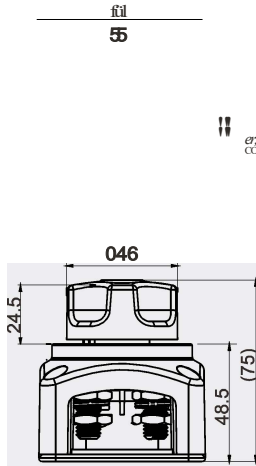

## FEATURES

- \* MATERIAL: Frames are PBT (UL frame: 94V-O), with black color.
- \* Actuator: PBT (UL frame: 94V-O), with red color.
- \* Wire screw for connection: copper tinned 2 pcs.
- \* Wire nut for connection: bronze tinned 4 pcs.
- \* Wire outlet direction: any of 4 directions.
- \* Actuator out=>OFF needs under the strength to press revolving.

## Circuit diagram

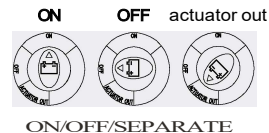

Continuous Rating

200A 12-50V DC

300A50V DC

Intermittent Rating

300A

Cranking Rating

1250A

Contact resistance

50mQ Max Insulation

resistance DC 1000V

100Mn Min Dielectric

Dielectric strength

DC 2000V 1 minute

AC 1250 1 minute

Cut out

