


A-A SECTION

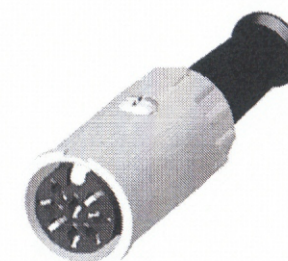

| | | | | |
|------------|--------------------|-----------------|--------------|-------------|
| 6 | Contact Terminals | Brass | Silver Ptd. | 8 |
| 5 | 8P270 Housing | PA66 | | 1 |
| 4 | Strain Boot | PVC | | 1 |
| 3 | Setscrew | Steel | Nickel Ptd. | 1 |
| 2 | "T" Cable Holder | Steel | Nickel Ptd. | 1 |
| 1 | Shell Cover | Zn Alloy | Nickel Ptd. | 1 |
| No. | Description | Material | Treat | Q'ty |

Specifications

rating :
 100V AC 1A MAX
 contact resistance :
 pins-30mΩ MAX; shell-50mΩ MAX
 Insulation resistance :
 MIN 100 MEGΩ @500V DC
 voltage withstand :
 250V AC R.M.S. for 1 minute