


RoHS COMPLIANT

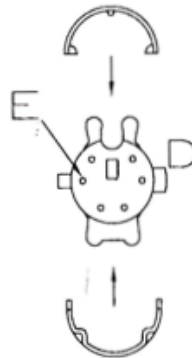

- SPECIFICATIONS:**
1. RATING: 11V AC 1A MAX OR 12V DC 2A MAX.
 2. INSULATION RESISTANCE: 50M OHM MIN AT 500V DC.
 3. DIELECTRIC STRENGTH: 500V AC / 1 MINUTE.

	7.0φ BACK SHELL
	6.0φ BACK SHELL
X	5.0φ BACK SHELL (STANDARD)
	COVER DIM.

TABLE A

MATERIAL:
 A. COVER: PE+2L
 B. SHELL: ABS
 C. METAL SHIELD:
 BRASS NICKEL PLATED
 D. HOUSING: NYLON66+GF
 E. CONTACT:
 BRASS SILVER PLATED