


RoHS COMPLIANT

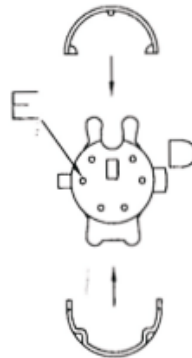

**SPECIFICATIONS:**

1. RATING: 11V AC 1A MAX  
OR 12V DC 2A MAX.
2. INSULATION RESISTANCE:  
50M OHM MIN AT 500V DC.
3. DIELECTRIC STRENGTH:  
500V AC / 1 MINUTE.

	7.0φ BACK SHELL
	6.0φ BACK SHELL
X	5.0φ BACK SHELL (STANDARD)
	COVER DIM.

TABLE A

**MATERIAL:**

- A. COVER: PE+2L
- B. SHELL: ABS
- C. METAL SHIELD:  
BRASS NICKEL PLATED
- D. HOUSING: NYLON66+GF
- E. CONTACT:  
BRASS SILVER PLATED