
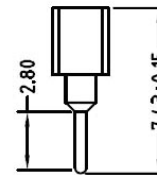
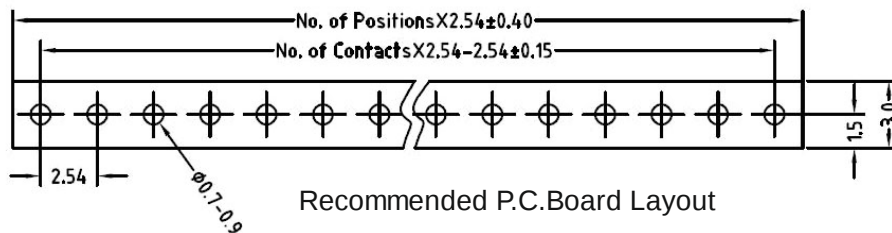
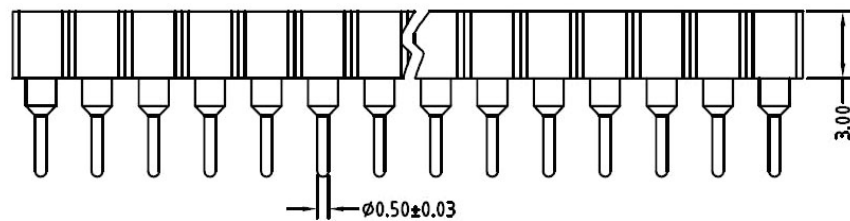


Datenblatt

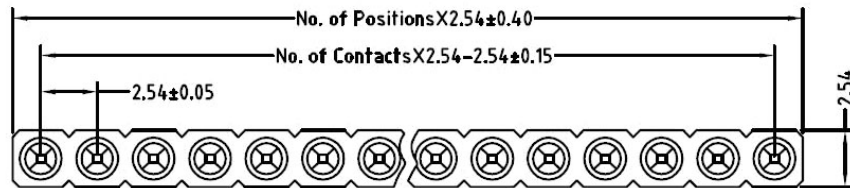

SPECIFICATIONS

Current Rating: 3.0 A

Voltage Rating: 60V AC/DC

Contact Resistance: 4m Ω Max.

Insulator Resistance: 1000M Ω Min.

Operating Temperature: -40°C to +105°C

MATERIALS

Insulator: Glass Filled Thermoplastic

Polyster UL94V-0, Black

Pin: Brass, Machined CuZn38Pb2

Clip: Beryllium Copper

* RoHS & REACH compliant.