
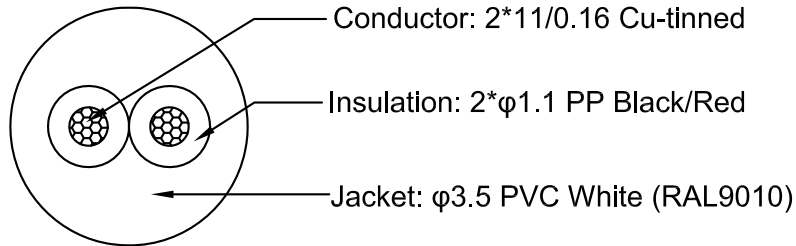



Datenblatt

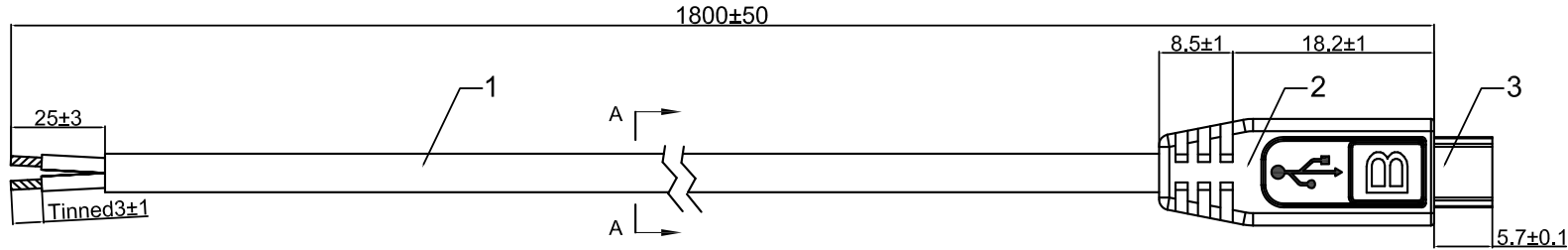

| Pin Connection | |
|----------------|------------|
| Pin | Connection |
| 1 | Red |
| 2 | n.c. |
| 3 | n.c. |
| 4 | n.c. |
| 5 | Black |

24 AWG CABLE

- ⚠ Electric Characters:
 1, Temperature Rating: 80°C
 2, Voltage Rating: 30V
 3, Insulation Resistance : PE DC-500V 100MΩ. Km Min at 20°C

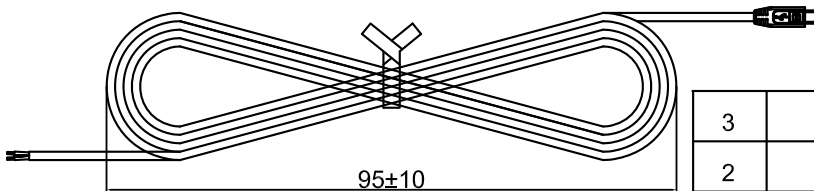

| | | | | |
|---|--|---------------------------|--------|----------------|
| 3 | | Micro USB B plug | 1pcs | Nickel-plate |
| 2 | | Micro USB 5P molding, PVC | 1pcs | White (RAL901) |
| 1 | | 24AWG*2C USB cable | 1800mm | White (RAL901) |

Attention: All materials must be in accordance with RoHS.