
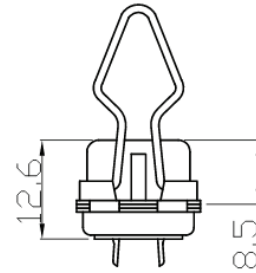
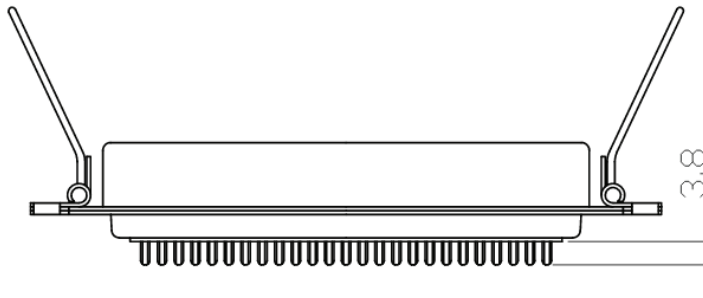


Datasheet

Item no. 1586421

V1_0617_02_EN

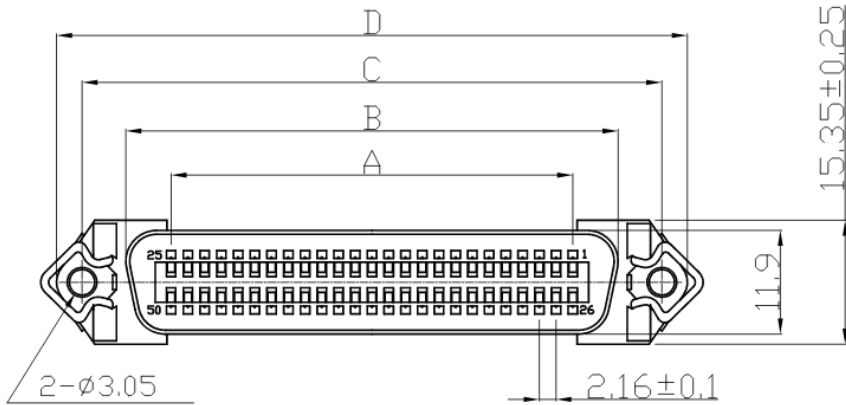

Dimensions

Positions	A	B	C	D
36	36.72	48.9	59.7	67.9

Material & finish

SHELL: Steel Zinc plated

PIN CONTACT: Brass Gold flash selective gold plated

INSULATOR: PBT & Glass-fibre reinforced UL 94V-0 Blue

NUMBER OF CONTACT: 14,24,36,50

CURRENT RATING: 5 Amp

DIELECTRIC STRENGTH: 1000V for one minute

INSULATOR RESISTANCE: 1000M Min. (at 500V DC)

TEMPERATURE: -55°C to +105°C

RoHS compliant