
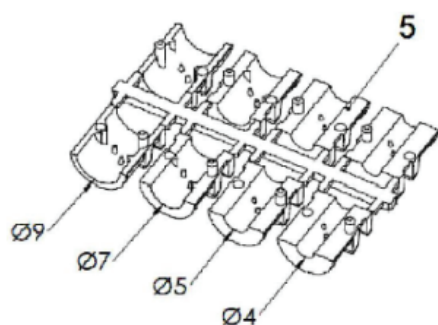
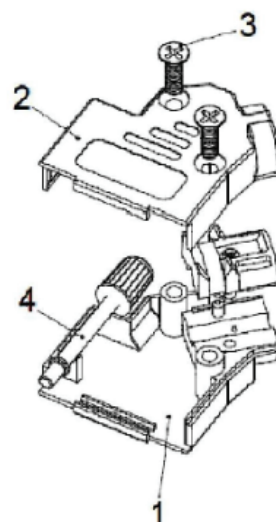
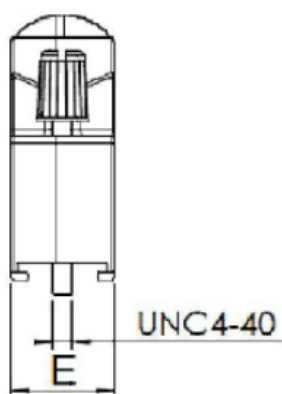



Datasheet

Item no. 1586429

V1_0617_02_EN

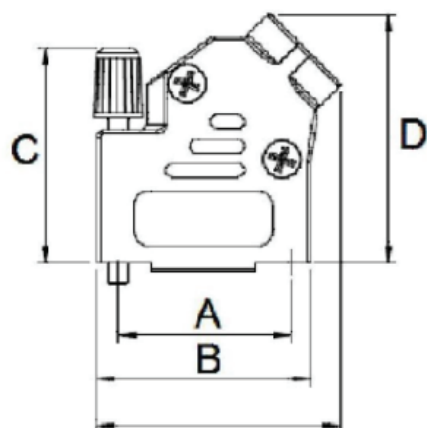

General Tolerances: ISO2768-m

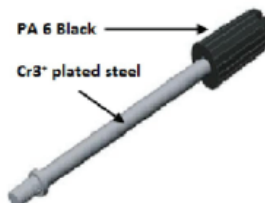

No. of contacts
09,15,25,37

Black anodized version on request

09-poles only with one knurledge screw available

Delivery includes

- 2 half-sheels
- 2 knurledge screws
- 2 screws
- 8 half shells of strain relief

SPECIFICATION MATERIAL Features

Material and finish
Zinc-die-cast,nickel plated

Temperature range
-40° to +120°

Cable diameter
4.0-13.0mm

Attenuation factor
>40 dB between
30Mhz and 1Ghz

Requirements
VDE 0871,FCC 20780,
89/336/EU

ITEM NO.	DESCRIPTION
1	Cover bottom
2	Cover top
3	Jack screws
4	Screws
5	Strain relief

Dimensions					
No. of contacts	A	B	C	D	E
09	25	31.0	31.3	36.2	14.6

RoHS compliant

Unit: mm

