
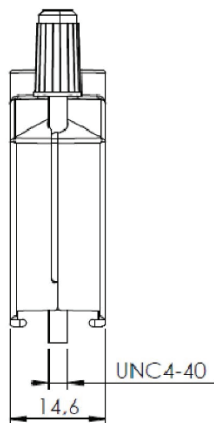
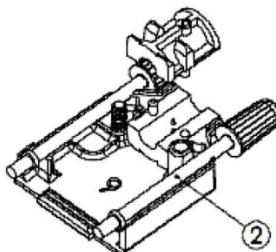
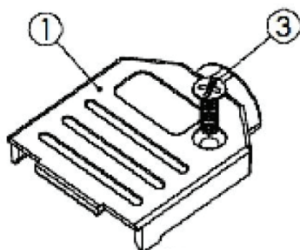
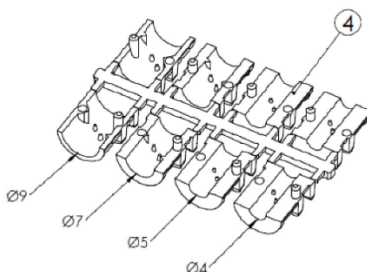


Datasheet

Item no. 1586431

V1_0617_02_EN

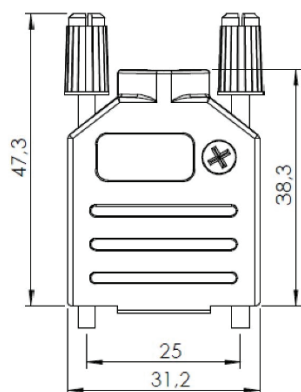

Plastic knop	Plating
Black	Black

Thread	
A	Plating
UNC4-40	Zink

SPECIFICATION

MATERIAL

Features

Material and finish

Zinc-die-cast,nickel plated

Temperature range

-40° to +120°

Cable diameter

4.0mm - 13.0mm

Attenuation factor

>40 dB between
30Mhz and 1Ghz

Requirements

VDE 0871,FCC 20780,
89/336/EU

Material

Zinc die-cast

Delivery includes

- | | | |
|---|------------------------------|------|
| 1 | half-sheels | (2x) |
| 2 | knurledge screws | (2x) |
| 3 | screw | (1x) |
| 4 | half shells of strain relief | (8x) |

