


Datasheet


Item no. 1586484

V1_0617_02_EN

Male

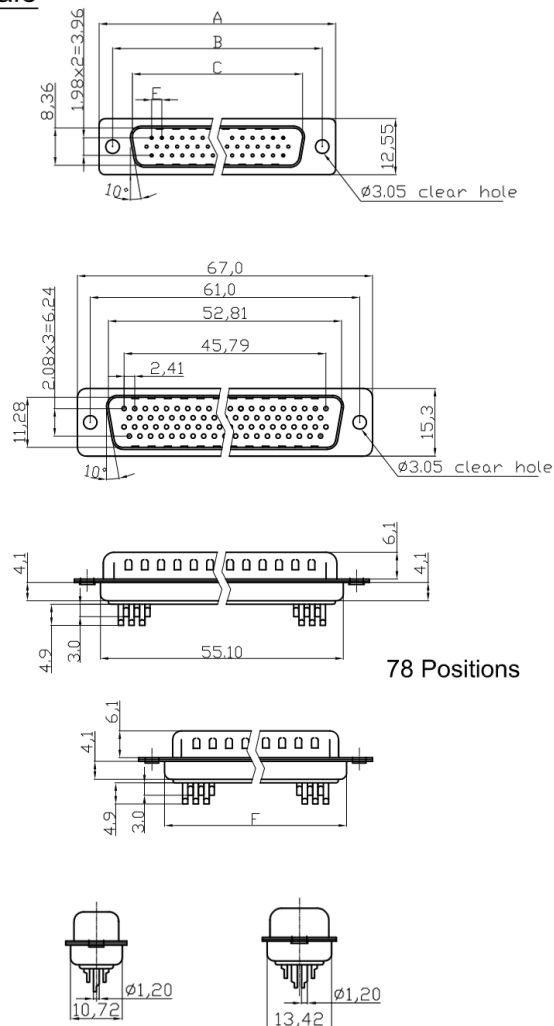

Female

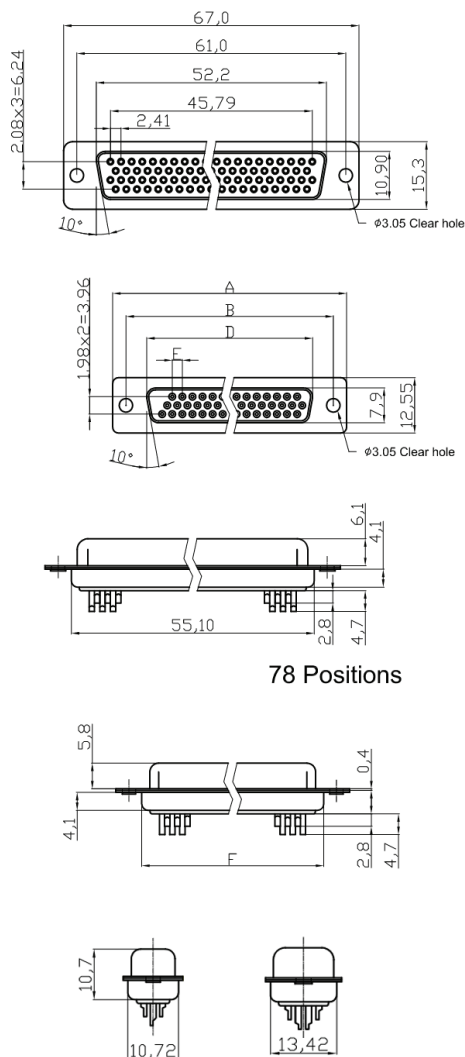

Dimensions					
Positions	A	B	C	E	F
26	39.20	33.30	25.25	2.29	27.70

Dimensions					
Positions	A	B	D	E	F
26	39.20	33.30	24.70	2.29	27.70

Product Specification

Material

Insulator :Glass-Filled Thermoplastic PBT,UL94V-0 rated,Black
Contact : Copper alloy, Gold flash selective gold plating
Shell : Steel, 100u" Tin Over 50u" min Copper

Electrical

Contact Resistance :20 milliohms Max at 1 AMP DC.
Insulation Resistance :1000magohms at 500 VDC
Dielectric Withstanding Voltage :1000 VAC/rms 60Hz for 1 minute
Current Rating : 3 AMP
Volatge Rating :250 VAC/rms 60Hz
Operating Temperature: -20°C ~ +85°C

NOTES:

MATERIAL

Insulator Material:Glass-filled thermoplastic PBT,UL94V-0 rated,Black
Contact Material:Copper alloy, Gold flash selective gold plating
Shell :Steel, 100 μ" Tin Over 50μ" min Copper

Electrical

Contact Resistance :20 milliohms Max at 1 AMP DC.
Insulation Resistance :1000magohms at 500 VDC
Dielectric Withstanding Voltage1000 VAC/rms 60Hz for 1 minute
Current Rating :3 AMP
Volatge Rating :250 VAC/rms 60Hz
Operating Temperature: -20°C+85°C

RoHS compliant

Unit: mm



File No.: E198287