

## Rocker Switch (Red colour) 3V LED

# Kipphebel-Schalter

- Runde Bauform
- Funktion EIN-AUS mit unabhängig ansteuerbarer LED
- Approbationen VDE UL CSA SEMKO DEMKO NEMKO


### Allgemeine technische Daten

Schaltleistung	6 A 250 V <sub>AC</sub> 10 A 125 V <sub>AC</sub>
Elektrische Lebensdauer (6A 250V <sub>AC</sub> )	10.000
Anschlüsse	4,8 x 0,8 mm Fast-On (LED - Lötflähen)
Übergangswiderstand (Neuzustand)	< 50 mΩ
Isolationswiderstand (Neuzustand)	> 100 M Ω (500V)
Hochspannungsfestigkeit	1.500 V <sub>AC</sub> / 1 min.
Kontaktöffnung	< 3 mm
Isolationsabstand	> 8 mm
Material Korpus und Wippe	Nylon 66
Entflammbarkeit	UL 94 V2
Geeignet für Geräte der Schutzklasse 2	

I<sub>f</sub> 20 mA

V<sub>f</sub> 2.1 V

### Abmessungen

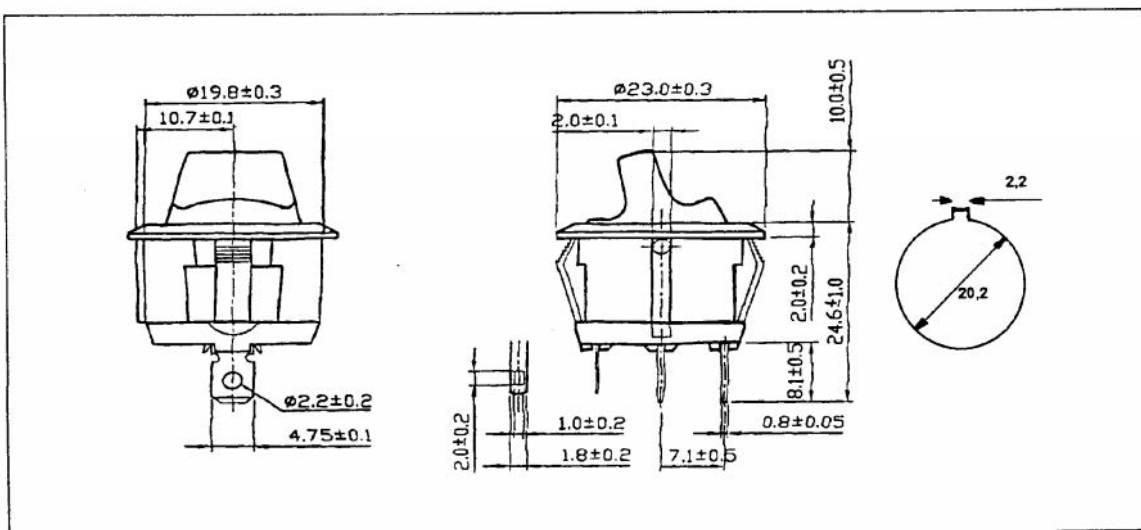

Unit: mm

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com).

All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represents the technical status at the time of printing.

© Copyright 2017 by Conrad Electronic SE.