
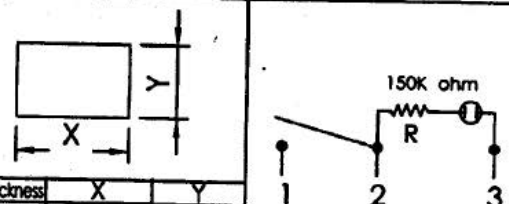


Rocker Switch RED (250VAC 150KR)

Rating	16A 125V AC 1/8HP 10A 250V AC 1/3HP cULus	Mounting Hole	Diagram											
	10A 250V ~ T85													
Contact Resistance	50m ohm Max.													
Insulation Resistance	DC 500V 100M ohm Min.													
Dielectric Strength	AC 1500V 1 minute													
Operation Temperature	-20°C~85°C													
Switch Function	3P SPST ON-OFF (Illuminated)													
		<table border="1"> <tr> <th>Panel Thickness</th> <th>X</th> <th>Y</th> </tr> <tr> <td>0.75...1.25</td> <td>19.2-0.1</td> <td>13+0.1</td> </tr> <tr> <td>1.25...2</td> <td>19.4-0.1</td> <td>13+0.1</td> </tr> <tr> <td>2...3</td> <td>19.8-0.1</td> <td>13+0.1</td> </tr> </table>	Panel Thickness	X	Y	0.75...1.25	19.2-0.1	13+0.1	1.25...2	19.4-0.1	13+0.1	2...3	19.8-0.1	13+0.1
Panel Thickness	X	Y												
0.75...1.25	19.2-0.1	13+0.1												
1.25...2	19.4-0.1	13+0.1												
2...3	19.8-0.1	13+0.1												

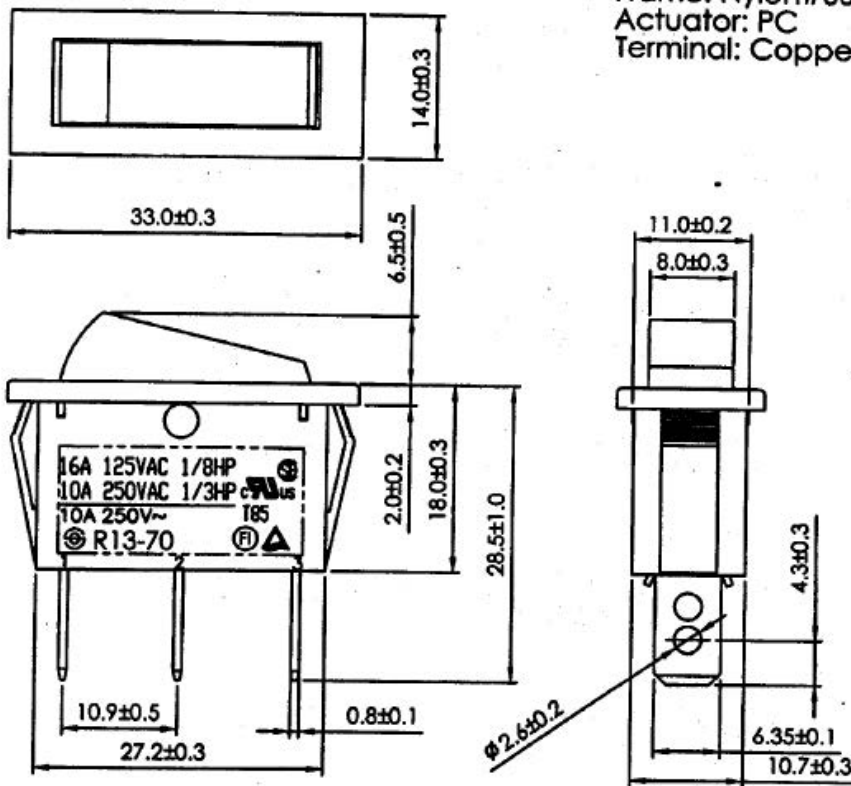

*** Material**

Frame: Nylon#66, Black

Actuator: PC

Terminal: Copper alloy , Silver plated

1820555	Green Clear
1820545	Yellow Clear
1820532	Red Clear
SCI NO.	Lens Color

Unit: mm