
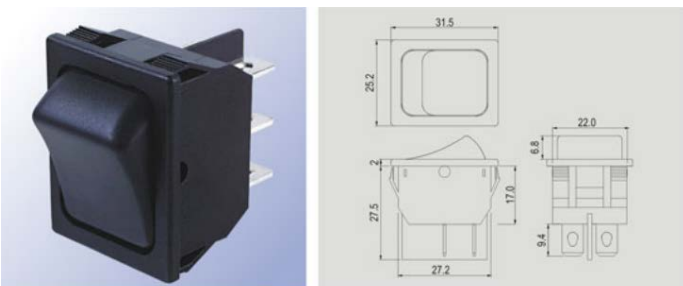



Rocker Switch Green

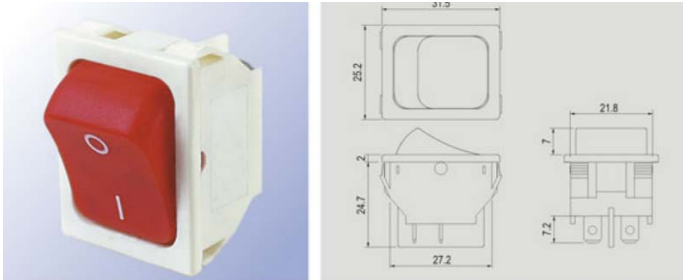


Rating
16A 125V AC 10A 250V AC
Contact resistance
50mΩ Max
Insulation resistance
DC 500V 100MΩ Min
Dielectric strength
AC 1500V 1 minute
Cut-out

FEATURES

- * MATERIAL: Frames are nylon (UL flame: 94V-2). Terminals are silver plated brass.
- * Illuminated actuators are molded in PC, available with red, amber and green colors.
- * Snap-in mounting, easy to install switch into panel.
- * Waterproof cover is optional.

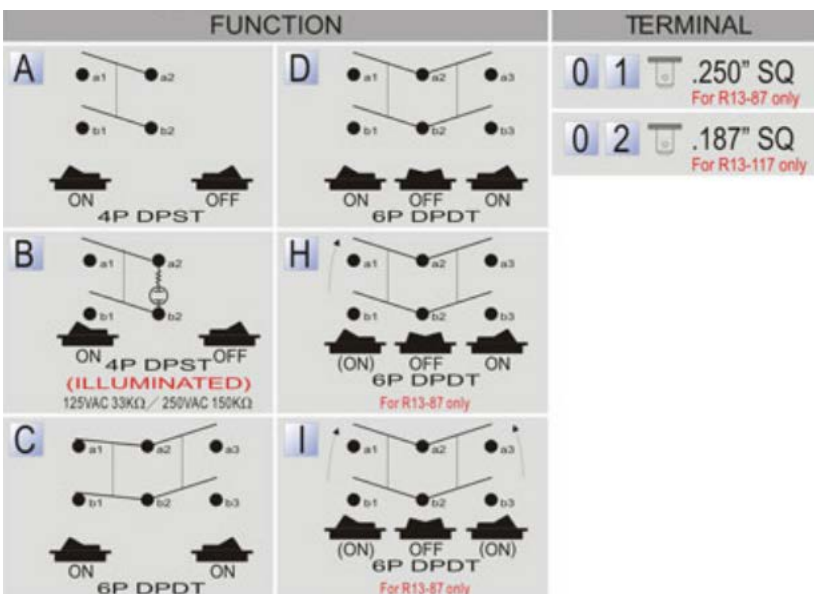

* () =momentary

	X		
	Y		
	X	Y	
0.75-1.25	30.2-0.1	22.2+0.1	
1.25-2	30.4-0.1	22.2+0.1	
2-3	30.8-0.1	22.2+0.1	

Unit: mm